



Connectors > Power Connectors > Circular Power > Circular Power Connectors



Number of Positions: 22

Connector Product Type: **Housing**

Operating Voltage: **600 VDC**

Connector System: **Wire-to-Panel**

Sealable: **Yes**

Features

Product Type Features

Connector Seal & Plug Type	Peripheral
Connector Product Type	Housing
Connector System	Wire-to-Panel
Sealable	Yes
Connector & Contact Terminates To	Wire & Cable
Connector & Housing Type	Receptacle
Circular Connector Shell Type	All Plastic

Configuration Features

Reverse Numbering	Without
Number of Positions	22
Number of Power Positions	2
Number of Signal Positions	20

Electrical Characteristics

Operating Voltage	600 VAC
-------------------	---------



Contact Features

Reverse Gender	No
Contact Type	Pin
Contact Protection	With

Termination Features

Termination Method to Wire & Cable	Crimp
------------------------------------	-------

Mechanical Attachment

Panel Mount Feature Type	Flange with Mounting Holes
Mating Alignment Type	Keyed
Mating Retention Type	Threaded Coupling
Mating Alignment	With
Thread Size	1-3/8 - 18 UNEF-2A
Connector Mounting Type	Panel Mount
Mating Retention	With
Panel Mount Feature	With

Housing Features

Body Orientation	Straight
Housing Color	Black
Housing Material	PA 6.6 GF
Circular Connector Shell Size	23

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
Fluid Resistance	None

Operation/Application

Circuit Application	Power & Signal
Shielded	No

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Quantity	1
Packaging Method	Standard



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 206612-1
CPC PLUG ASSEMBLY SIZE 23-22



TE Part # 206612-2
CPC PLUG ASSEMBLY SIZE 23-22

Also in the Series | AMP Circular Plastic Connectors




Circular Connector Backshells & Clamps(1)



Circular Power Connectors(423)




Connector Contacts(6)

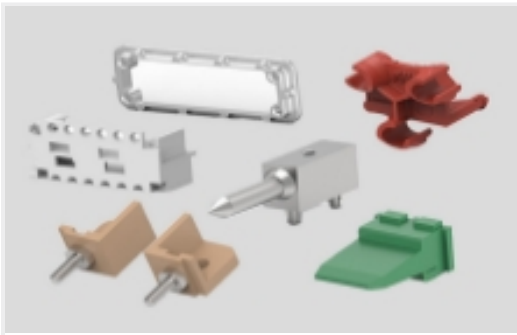

Connector Hardware(10)



Power Contacts(6)

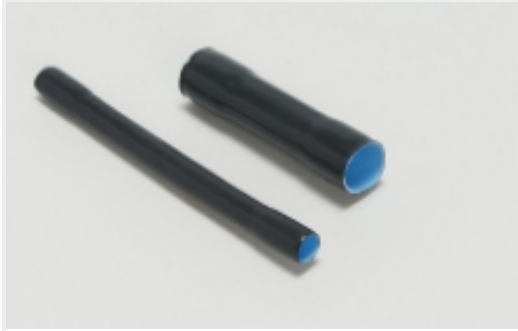


Sealing Sleeves(2)

Customers Also Bought



TE Part #1-66101-7
III+ SKT,18-16,15AU/FL,SMPACK

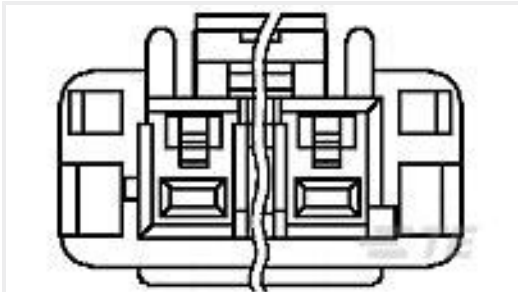

TE Part #1376388-1
5MM POWER KEY 2P PLUG HSG NAT



TE Part #344111-1
36W EMS.REC. HSG.ASSY




TE Part #206612-1
CPC PLUG ASSEMBLY SIZE 23-22



TE Part #206060-2
CPC PLUG,SZ 11-4,SMALL PACK



TE Part #5054422013
RNF-100-1/8-5-STK

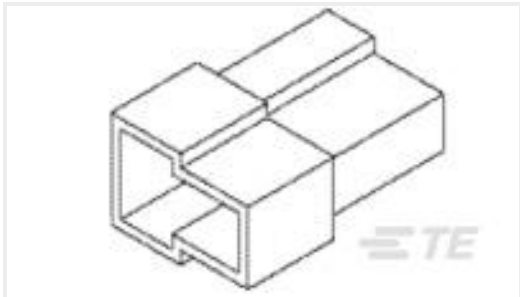

TE Part #1-180908-0
FF 250 TAB HSG 2P NYLON NAT



TE Part #63824-1
250 FASTON TAB TPBR



TE Part #641922-3
08P MTA156 HDR ASSY STR W/O#2



TE Part #638444-9
HEADER ASSEMBLY R/A UNSEALED 1

Documents



Product Drawings

RECEPT,SZ 23-22,CPC,W/SEAL

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_206613-5_AN.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_206613-5_AN.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_206613-5_AN.3d_stp.zip

English

3D PDF

3D

3D PDF

English

Customer View Model

ENG_CVM_206613-5_P1.2d_dxf.zip

English

Customer View Model

ENG_CVM_206613-5_P1.3d_igs.zip

English

Customer View Model

ENG_CVM_206613-5_P1.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Connector, Circular Plastic

English

Product Specification

English

Agency Approvals

UL Report

English