


# ball valve QH-3/4

Part number: 9544

FESTO

with hand lever.

This type is suitable for vacuum.

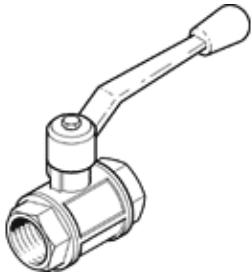

## Data sheet

Feature	Value
Valve function	2/2 bistable
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 2	G3/4
Type of actuation	manual
Mounting type	Line installation
Standard nominal flow rate	21,000 l/min
Nominal size	20 mm
Ambient temperature	-20 ... 180 °C
Material housing	Brass
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water
Sealing principle	soft
Design structure	Ball valve
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)