


HOSE TAILS

Parallel female thread hose tail with
swivel nut - JFTT

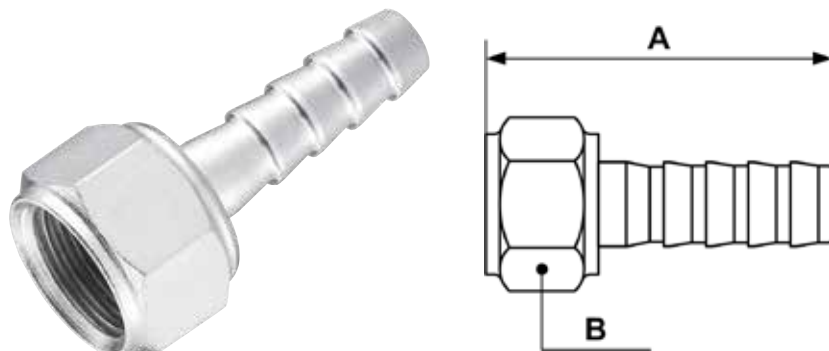

Min / Max operating pressure

0 / 15 bar

Part number	Female thread	Dim. A (mm)	Dim. B (mm)
JFTT 1406	G1/4	39	16
JFTT 1408	G1/4	39	16
JFTT 1213	G1/2	41	23