

ELED-60-D Series

60W Dali Dimmable Driver




CE DALI

Features:

- Dali dimmable
- Constant current and constant voltage design
- Protections: Short circuit/ Overload/ Over voltage
- Built-in PFC function (PFC>0.95)
- Cooling by free air convection
- Up to 80% efficiency
- Fully isolated, delivering up to 60W of power
- Dali control standard IEC62386
- Dali control input <2mA, 1-100% logarithmic dimming range

Model No.	ELED-60-350D	ELED-60-700D	ELED-60-12D	ELED-60-24D
Input Voltage Range	220-240VAC			
AC Frequency	50-60Hz			
Output Type	Dual			Single
Output Mode	Constant Current		Constant Voltage	
Output Current	350mA	700mA	0-4.0A	0-2.0A
Output Voltage	60-72V	36-42V	12V	24V
Output Power	60W Max.			
Power Factor	>0.95			
Efficiency	>80%			
Operating Temperature	-30°C~+45°C			
Relative Humidity	5-95%			
Isolation Voltage	In/ Out 3000VAC			
Vibration	5-55Hz/ 2g, 30 minutes			
EMI	EN55022, EN55015 Class B			
Safety	EN61347-1, EN61347-2-13			
Electromagnetic Immunity	EN61547, EN55024, EN61000-4-2, 3, 4, 6, 8, 11			
Harmonic Current Emissions	EN61000-3-2, EN61000-3-3			
Dimensions (mm)	123x 79x 35			

Dimensions Chart(mm)

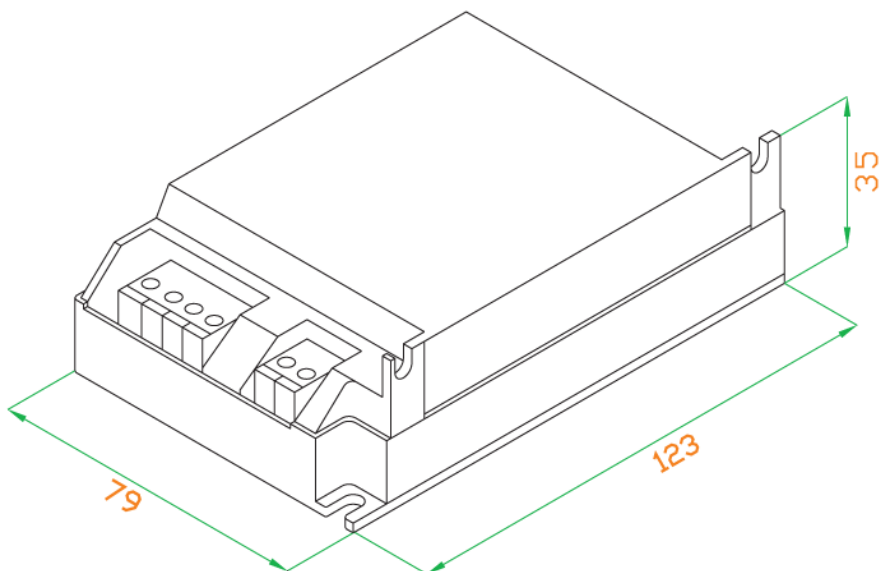

Wiring Schematic

