


Product Name // M12 Series X Code TPU Inline to Flex

Body Overmould Cable Connector 8 Contact Plug Pre-Wired

With 5M PU Jacket Cable

 View Product Page

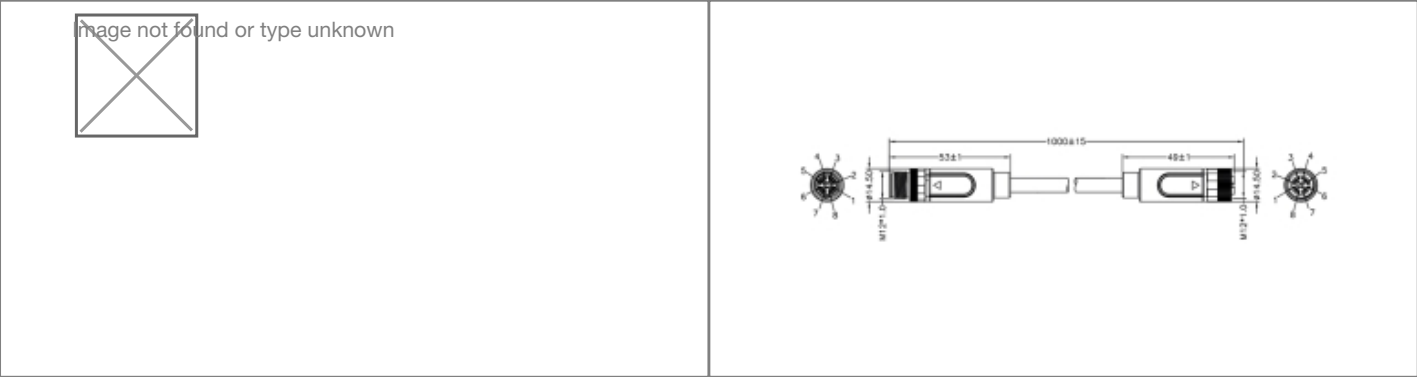

// Product Description:

- M12 Series Overmould Inline Connectors
 - Water and dustproof to IP67 when mated with compatible connector
 - Pin or Socket
 - 3, 4, 5, 8, 12 Contact (3,12 Contact are A Code, 4 Contact are choice of A Code or D Code, 5 Contact are choice of A Code or B Code, 8 Contact are choice of A Code or X Code)
- PCB Terminals
 - Choice of mounting nut sizes, depending on part code
 - Choice of Sealing Caps available separately to maintain IP rating of unmated connectors
 - Mate with M12 Series Inline Body and Flex Body Connectors, depending on part code

// General Information:

Product Display Title:	M12 Series Overmould Inline Connectors
Product Family:	Circular Automation Connectors
Product Series:	M12 X Coding Series
Body Material:	TPU
Contact Type:	Socket Contact
Coupling Type:	M12
Current Max:	0.5A
Function:	Overmould Inline Connector
Ip Rating:	IP67
Max Operating Temperature:	+85°C
Min Operating Temperature:	-25°C
Number Of Contacts:	8 Contacts
Sheath Material:	PUR
Voltage Max:	48V

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



Click Here To Contact Us