



TCJ70-XL


Flanged housing unit

Housing units TCJ, four-bolt flanged housing units, cast iron, eccentric locking collar, T seals

Schaeffler ID:
0947479540000

X-life

Technical information

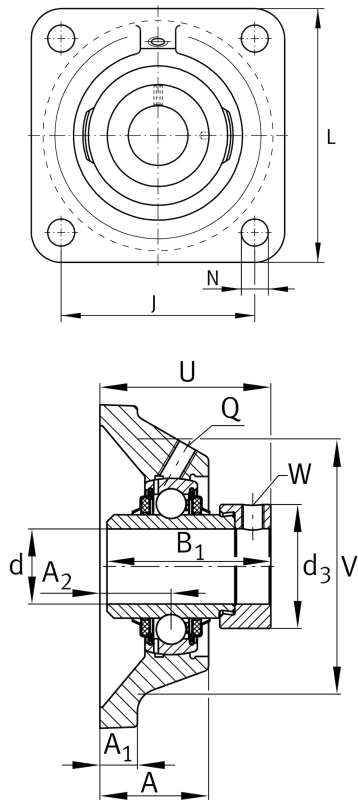

Your current product variant

Material	GG	Grey cast iron
----------	----	----------------

Main Dimensions & Performance Data

d	70 mm	Bore diameter
L	188 mm	Flange width
U	82,6 mm	Total height unit
C _r	66.000 N	Basic dynamic load rating, radial
C _{0r}	44.000 N	Basic static load rating, radial
C _{ur}	2.300 N	Fatigue load limit, radial
≈m	5,45 kg	Weight

Mounting dimensions

J	150 mm	Distance fixing bore
N	18 mm	Fixing bore
W	6 mm	Width across flats
n	4	Number of screwing holes



Dimensions

A	52 mm	Height housing
A ₁	18 mm	Thickness of flange
A ₂	38 mm	Distance raceway
B ₁	66 mm	Locking collar total width
V	165 mm	Shoulder diameter housing
Q	M6	Connection thread for lubrication
d ₃	96 mm	Outside diameter locking device

Additional information

1	Number of housings
CJ14	Housing
GE70-XL-KTT-B	Bearing designation

Temperature range

T _{min}	-20 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.