

Actuator

704.022.7

Distribution by
Rs-online



<https://rs-online.eao.com/p/704.022.7>

Your product:



704.022.7 Actuator

FRONT

Front dimension: Ø 29 mm

Front form: Round

MOUNTING

Design: Raised

Mounting type: Panel mounting

OPERATING-/INDICATION PART

Lens cap colour: Colourless

Lens cap material: Plastic

Lens cap optical effect: translucent

Marking cap colour: White

Marking cap optics: translucent

ELECTRICAL CHARACTERISTICS

Standards: The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1

MECHANICAL CHARACTERISTIC

Terminal: Screw terminal

Weight: 0.025 kg

AMBIENT CONDITION


IP Protection: IP65 front side
Operating temperature: - 40 °C ... + 55 °C
Storage temperature: - 40 °C ... + 85 °C

CERTIFICATE


REACH: REACH compliant
RoHS: RoHS compliant

OTHER

Short Description: Actuator, Ø 29 mm, Round, Screw terminal
Housing colour: Grey
Housing material: Plastic
Product attributes: Filament lamp 130 V, max. 2.6 W with integrated series resistor 230/130 V
Wiring diagrams:

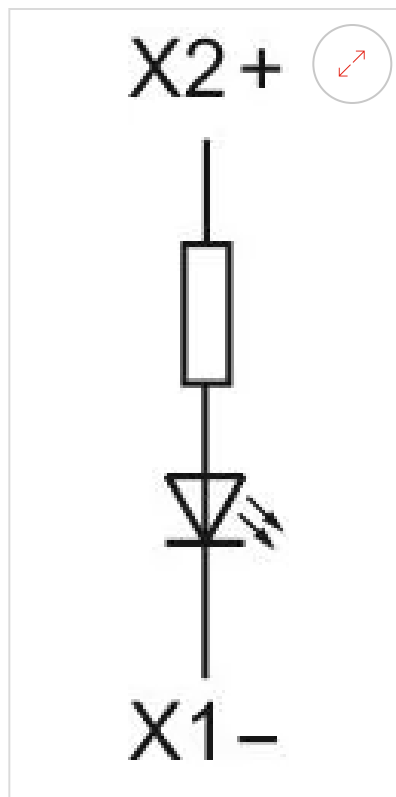

Mounting cut-outs:

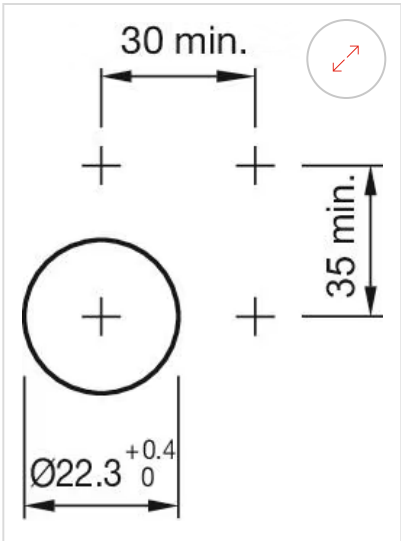

Dimension drawings:

