

SET OF 242 TOOLS FOR BODY

CP-242CAR

SAM Outillage


10 rue Camille de RochetaillÃ©e
42000 Saint-Etienne - France

RCS Saint-Etienne B 338 002 231 | SAS au capital de 8 189 583 â,-

<https://www.sam-outillage.com/>

Photos and texts not contractually binding. Do not litter. Document generated on 2025-07-18 08:52:52



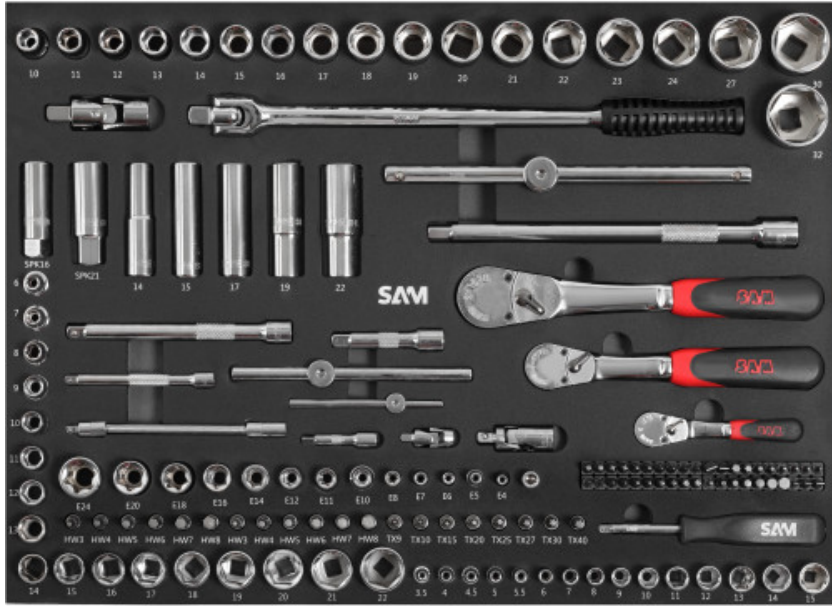

SAM Outillage

10 rue Camille de RochetaillÃ©e
42000 Saint-Etienne - France

RCS Saint-Etienne B 338 002 231 | SAS au capital de 8 189 583 Å.-

<https://www.sam-outillage.com/>

Photos and texts not contractually binding. Do not litter. Document generated on 2025-07-18 08:52:52



DESCRIPTION

SET OF 242 TOOLS FOR BODY

Set of 242 tools suitable for light-vehicle bodywork tasks.

SPECIFIC DATA

Designation	SET OF 242 TOOLS FOR BODY
Sales reference	CP-242CAR
Weight (kg)	26.000
Width (mm)	440
Length (mm)	270
Height (mm)	650
Guarantee	O SAM TOOL guarantee.

Guarantee applied

O | SAM TOOL guarantee.

Guarantee without time limit on the tools used under normal conditions.

>> [Find out more](#)

Toolset



x 1

Foam module 3/3 of 10 bodywork tools- flattening hammers
295-J10M



x 1

Bodywork empty foam module
MOD-56


SAM Outillage


10 rue Camille de RochetaillÃ©e
42000 Saint-Etienne - France


RCS Saint-Etienne B 338 002 231 | SAS au capital de 8 189 583 Å,-

<https://www.sam-outillage.com/>




 x 1
Round face dinging hammer
295-2A


 x 1
Bumping hammers
295-...A
Ref : 295-10A


 x 1
Cross-hatched head mallet
296-2A


 x 1
Flat planishing mallet
296-4A


 x 1
Convex planishing mallet
296-10A

 x 1
Us type dolly block
95-2A

 x 1
Comma type dolly block
95-4A

 x 1
Thin anvil dolly block
95-6A


 x 1
Extra-flat dolly block
95-24A


 x 1
Wooden mallet
307-51




x 1

Selection of screwing tools - foam module 3/3
CP-37PM

 x 14
Combination wrenches in mm
50A-...
Ref : 6 - 7 - 8 - 9 - 10 - 11 - 12 - 13 - 14 - 15 - 16 - 17 - 18 - 19

 x 3
Electrician's slotted screwdriver
TA-...E
Ref : TA-3E50 - TA-4E100 - TA-55E125

 x 2
Electrician's tom thumb slotted screwdriver
TA-...E40
Ref : TA-4E40 - TA-55E40

SAM Outillage






10 rue Camille de RochetaillÃ©e
42000 Saint-Etienne - France

RCS Saint-Etienne B 338 002 231 | SAS au capital de 8 189 583 Å,-

<https://www.sam-outillage.com/>









Photos and texts not contractually binding. Do not litter. Document generated on 2025-07-18 08:52:52



	x 2	Mechanic's slotted screwdriver TA-...M Ref : TA-65M150 - TA-8M150
	x 2	Phillips® screwdriver TA-...P Ref : TA-1P100 - TA-2P125
	x 2	Phillips® screwdriver TA-...P40 Ref : TA-1P40 - TA-2P40
	x 2	Phillips® screwdriver TA-...PZ Ref : TA-1PZ100 - TA-2PZ125
	x 10	Torx® screwdriver TA-...X Ref : TA-6X50 - TA-7X50 - TA-8X50 - TA-9X75 - TA-10X75 - TA-20X100 - TA-25X100 - TA-27X100 - TA-30X125 - TA-40X125



x 1 Selection of tightening tools - foam module 3/3
CP-138PM

	x 1	Screw driving bits ph + hex E-900J10 Ref : E-900J10
	x 1	Screw driving bits pz +tx E-910J10 Ref : E-910J10
	x 1	Screw driving bits fte +txr E-920J10 Ref : E-920J10
	x 1	3/8" sliding handle J-120 Ref : J-120
	x 1	1/2" site ratchet with lever reversion J-157B Ref : J-157B
	x 2	Straight 3/8" extensions J-2... Ref : J-208 - J-210
	x 1	3/8" joint J-240 Ref : J-240
	x 17	3/8" short hexagonal sockets in mm JH-... Ref : 6 - 7 - 8 - 9 - 10 - 11 - 12 - 13 - 14 - 15 - 16 - 17 - 18 - 19 - 20 - 21 - 22

SAM Outillage















10 rue Camille de RochetaillÃ©e
42000 Saint-Etienne - France








RCS Saint-Etienne B 338 002 231 | SAS au capital de 8 189 583 Å.,-

<https://www.sam-outillage.com/>

Photos and texts not contractually binding. Do not litter. Document generated on 2025-07-18 08:52:52









	x 2	LONG SOCKET 6-FLAT 3/8" 28 MM JHL-... Ref : 16 - 21
	x 5	3/8" sockets for Torx® head JTX-... Ref : 10 - 11 - 12 - 14 - 16
	x 15	1/4" short hexagonal key socket (mm) R-...Douilles_1/4_MM Ref : 3,5 - 4 - 4,5 - 5 - 5,5 - 6 - 7 - 8 - 9 - 10 - 11 - 12 - 13 - 14 - 15
	x 1	1/4" sliding handle R-120 Ref : R-120
	x 1	Site 1/4" ratchet R-157B Ref : R-157B
	x 2	Straight 1/4" extensions R-21... Ref : R-210 - R-211
	x 1	Flexible 1/4" extension R-220 Ref : R-220
	x 1	Fitted 1/4" extension R-225 Ref : R-225
	x 1	1/4" joint R-240 Ref : R-240
	x 1	1/4" bit holder socket RD-1 Ref : RD-1
	x 6	1/4" single-piece screwdriver sockets for hollow hexagonal screws RS-... Ref : 3 - 4 - 5 - 6 - 7 - 8
	x 1	Sets of 6 screwdriver sockets 1/4" for 6-flat socket head screws on storage rack RS-J6R Ref : RS-J6R
	x 1	Set of 8 screwdriver sockets 1/4" for Torx® imprint on storage rack RT-J8R Ref : RT-J8R
	x 5	1/4" sockets for Torx® head RTX-... Ref : 4 - 5 - 6 - 7 - 8

	x 1	1/2" sliding locking handle S-120 Ref : S-120
	x 1	1/2" site ratchet with lever reversion S-157B Ref : S-157B
	x 1	Straight 1/2" extensions S-2... Ref : S-215
	x 1	1/2" joint S-240 Ref : S-240
	x 18	1/2" short hexagonal sockets in mm SH-... Ref : 10 - 12 - 13 - 14 - 15 - 16 - 17 - 18 - 19 - 20 - 21 - 22 - 23 - 24 - 27 - 30 - 32
	x 5	1/2" long bi-hexagonal sockets in mm SL-...Douilles_MM Ref : 14 - 15 - 17 - 19 - 22
	x 3	1/2" sockets for Torx® head STX-... Ref : 18 - 20 - 24



x 1

Selection of pliers - hammers - foam module 3/3
CP-48PM

	x 1	Bodyworker's chisel 1-... Ref : 1-B
	x 1	Polished chrome-plated universal pliers 204-...G Ref : 204-16G
	x 1	Polished burnished finish stacked-branch multigrip pliers 209-25PA Ref : 209-25PA
	x 1	Chrome-plated polished diagonal cutting pliers 232-...G Ref : 232-16G
	x 1	Riveting hammers 310-...N Ref : 310-32N
	x 1	Mallets with interchangeable tips 320-...D Ref : 320-32D

SAM Outillage

10 rue Camille de RochetaillÃ©e
42000 Saint-Etienne - France

RCS Saint-Etienne B 338 002 231 | SAS au capital de 8 189 583 Å,-

<https://www.sam-outillage.com/>





x 1



x 1

Universal hand shears

331-16

Ref : 331-16



x 1

Rack of 9 Resistorx® male keys

59-R9A

Ref : 59-R9A



x 1

Rack of 9 hexagonal keys

62-R9A...

Ref : 62-R9A



x 1

Rack of 9 long 6-flat male keys 1/4"

63-R9A...

Ref : 63-R9A



x 1

Rack of 9 male 6-flat keys with spherical head in mm

67-AR9A

Ref : 67-AR9A



x 5

Long drift punches

7-...A

Ref : 7-25A - 7-35A - 7-50A - 7-70A - 7-90A

Foam module 3/3 of 9 bodywork tools

295-J9M



x 1

Bodywork empty foam module

MOD-57



x 1

High-capacity lock grip pliers

212-25



x 1

Lock grip pliers for high-precision welding

218-28



x 1

Sheet metal scroll shears

327-P-25-...

Ref : 327-P-25-D



x 1

Narrow bodywork spoon

95-42A



x 1

Wide bodywork spoon



95-44A



x 1

Double short bodywork spoons

95-48A

	x 1	Curved milled files LFC-35... Ref : LFC-35H
	x 1	Flexible frame for milled tooth file LM-36A

SAM Outillage

10 rue Camille de RochetaillÃ©e
42000 Saint-Etienne - France

RCS Saint-Etienne B 338 002 231 | SAS au capital de 8 189 583 Å,-

<https://www.sam-outillage.com/>

Photos and texts not contractually binding. Do not litter. Document generated on 2025-07-18 08:52:52

