

Datasheet

ENGLISH


RS PRO DC Motor, 24.6 W, 3 - 7.2 V dc, 107.3 gcm, 22356 rpm, 2.3mm Shaft Diameter

Stock No: 238-9721



Specifications:

Supply Voltage	3 – 7.2V
Power Rating	24.6 W
Output Speed	22356 rpm
Shaft Diameter	2.3mm
Maximum Output Torque	107.3 gcm
Length	38mm
Dimensions	27.7 (Dia.) x 38mm
Current Rating	5.25 A
Weight	69g

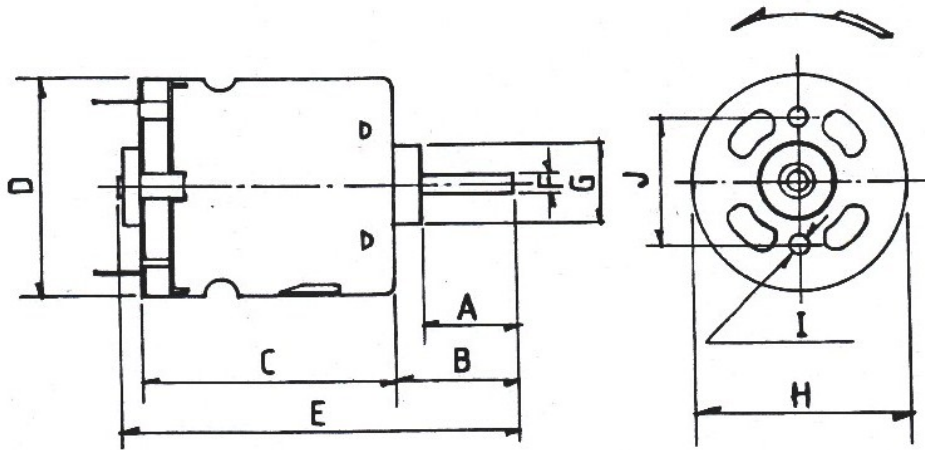

Dimensions	A	B	C	D	E	F	G	H	I	J
mm	14.55	17.15	37.8	27.7	57.15	2.30	10	27.7	M2.5x5 Taptite	16

Stall Current RE-380 at 7.2v = 11.2A