



229A - Boring bits



Description:

- For drilling, deburring, boring thin materials: press sheet, non ferrous metals.
- HSS steel.
- Max. thickness recommended: 4 mm.
- Does not require a tapping hole.

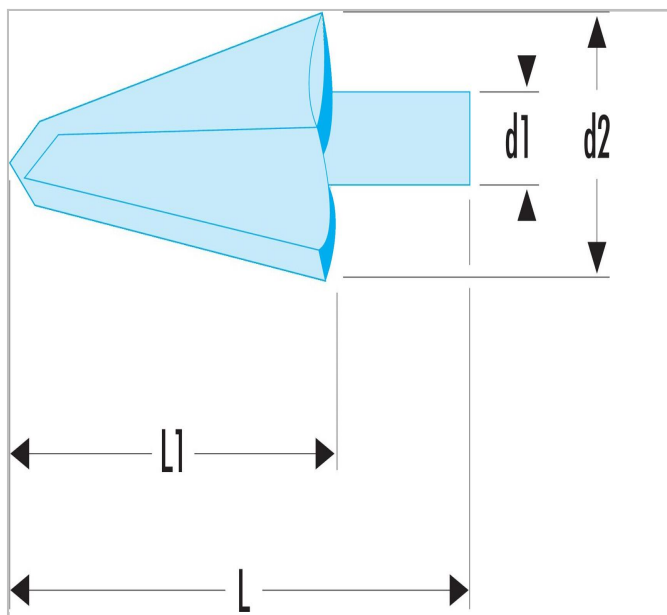

	Length L [mm]	Diameter D1 [mm]	Diameter D2 [mm]	Length L1 [mm]	Weight [g]
229A.1	59.0	6.0	3 - 14	37.0	25.0
229A.2	71.0	8.0	5 - 20	41.0	45.0
229A.3	76.0	9.0	16 - 30.5	48.0	130.0