




Datasheet

RS PRO DC FAN 30x10mm

Stock Number: 541-5413

EN

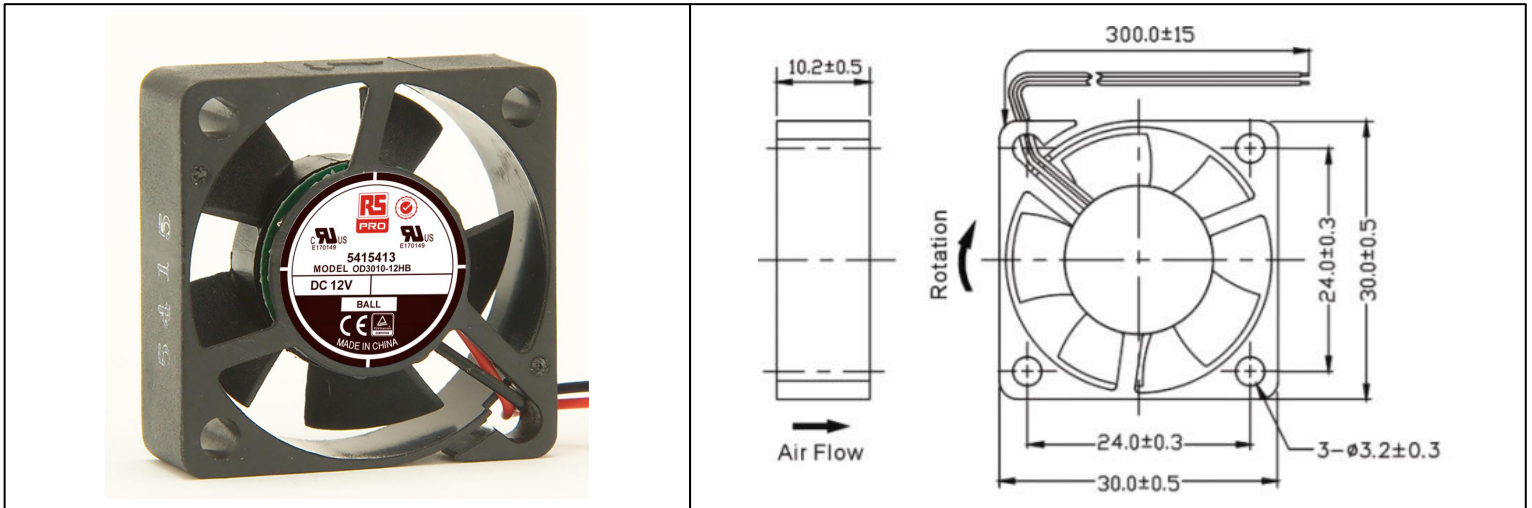

Frame	PBT UL94 V-0 Plastic	<p><u>Operating Temperature</u> -20°C ~ +75°C</p> <p><u>Storage Temperature</u> -40°C ~ +80°C</p> <p><u>Life Expectancy</u> 70,000 hours (L10 at 40°C)</p> <p>Weight: 0.01Kgs (0.02 lbs)</p>	
Impeller	PBT UL94 V-0 Plastic		
Connection	2x Wire Leads, 28AWG		
Motor	Brushless DC, Auto Cutoff, Auto Restart, Polarity Protected		
Bearing System	Dual Ball Bearings		
Dielectric Strength	500VAC/min < 1mA		
Insulation Resistance	10M ohm between leadwire and frame (500VDC)		

Model Number	541-5413
Rated Voltage	12 VDC
Voltage Range	9 ~ 13.2
Rated Current	0.10 A
Rated Speed (RPM)	10000
Airflow (CFM)	4.6
Noise Level (dB)	31
Max. Static Pressure	0.20" H ₂ O