




Application Tooling > Hand Crimping Tools

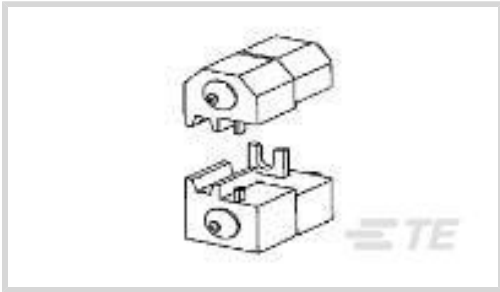

Tool Grade: **Premium Crimp Tooling**
Die Sets Type: **Removable/Interchangeable**
Specification Type: **MIL Spec, TE Product Specification (114-)**
TE Certification: **Yes – Certificate Included**
Power Technology Type: **Battery, Electric, Manual**

Features

Other

Crimp Form-Wire Barrel Type	Closed Barrel - Confined Crescent
Tool Grade	Premium Crimp Tooling
Die Sets Type	Removable/Interchangeable
Specification Type	MIL Spec, TE Product Specification (114-)
TE Certification	Yes – Certificate Included
Power Technology Type	Battery, Electric, Manual
Tooling Type	Die Assembly

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free






Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

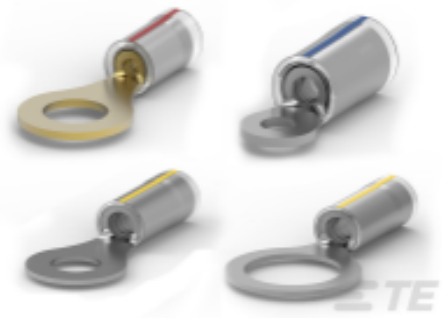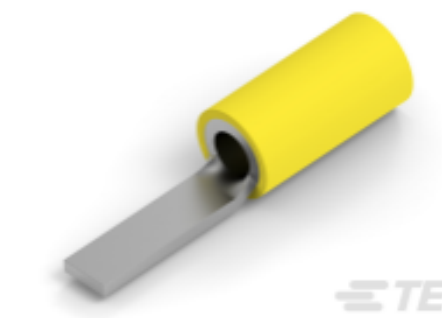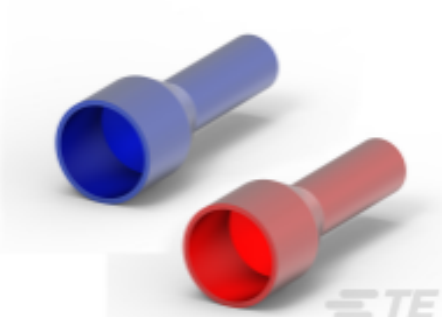 TE Part # CAT-P592-R472 PIDG Radiation Resistant C Rings /Spades	 TE Part # 1958193-1 PIDG 12-10 PVF2 WIRE PIN	 TE Part # 131445 PG, WIRE TAB, 12-10	 TE Part # 130203 PIDG RING
 TE Part # 160294 PLASTI-GRIP, RING, 12-10 6MM	 TE Part # 160300 PLASTI-GRIP 12-10 RING M10	 TE Part # 34826 TERMINAL, PG R 16-14HD 3/8	 TE Part # 34827 TERMINAL, PG R 16-14HD 1/2
 TE Part # CAT-P592-ST433 PIDG Stepdown Butt Splices	 TE Part # 34173 TERMINAL, PG R 12-10 3/8	 TE Part # 342066 16-14 H.D.R/T 1/2" STUD BLACK	 TE Part # 53982-1 TERMINAL, PIDG PVF2 R 16-14HD




TE Part # 2844990-1
KIT,BTLI,C HEAD



TE Part # 34835
TERMINAL,PG R 12-10 4



TE Part # 34854
TERMINAL,PG R 12-10 10

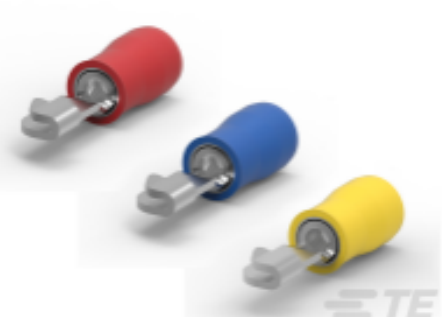

TE Part # CAT-P592-K742
PIDG Knife Disconnect Splices



TE Part # 34852
TERMINAL,PG R 12-10 6



TE Part # 35349
TERMINAL,PG R 16-14HD 1/4




TE Part # 696047-1
TERMINAL PG 12-10, 8




TE Part # 53963-1
TERMINAL,PIDG PVF2 R 16-14HD 4


Customers Also Bought

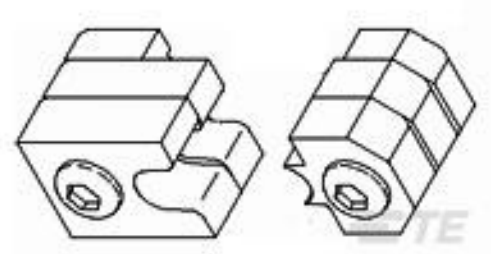


TE Part #47807-1
DIES PIDG 16-14 DIE SET

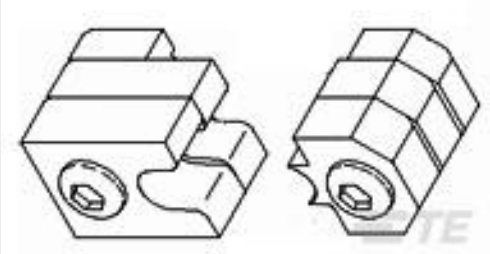

TE Part #69344
PIDG 26-22 DIE SET

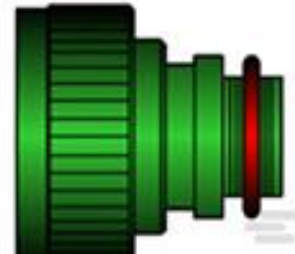

TE Part #653649-000
TXR32AB00-2210AI

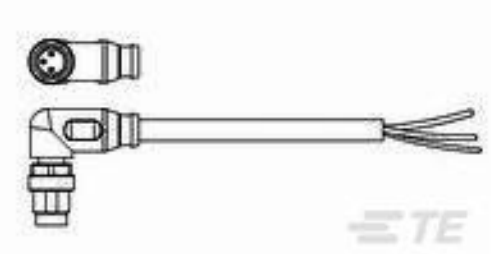

TE Part #2273008-2
M8 x 1.0 Angled plug Pigtail




TE Part #2150283-2
OCEAN_2.0_Applicator-E-080F130F-REA



TE Part #2170773-1
CAGE ASSY, QSFP28 1X1, SPRING, LP



TE Part #2-456406-5
WIRE CRIMPER .090

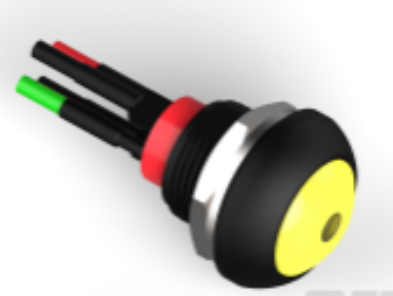

TE Part #1-2329389-1
PB OFF/ON FC YLW M1 TERM WHI LED IP68 50



TE Part #5-2176405-6
3550 10M 5%



TE Part #2-1618108-3
WOV-3-440=WILMAR OVERVOLTAGE 4

Documents



Datasheets & Catalog Pages

Bottoming Dies

English

Instruction Sheets

C-Head Adapter Battery Powered Crimp Tool Kit, PN 2844990-[]

C-Head Adapter Battery Powered Crimp Tool Kit, PN 2844990-[]

C-Head Adapter Battery Powered Crimp Tool Kit, PN 2844990-[]

German

C-Head Adapter Battery Powered Crimp Tool Kit, PN 2844990-[]

French

C-Head Adapter Battery Powered Crimp Tool Kit, PN 2844990-[]

C-Head Adapter Battery Powered Crimp Tool Kit, PN 2844990-[]

English