




147-1.1/4

**1-1/4" Open End Insert for 14 mm
x 18 mm Rectangular Connector
Wrench**



PRODUCT DETAILS

- Insert is fixed to the torque wrench by a spring-loaded retractable pin
- Range covers 9x12 and 14x18 receivers, from 1/4 to 1.1/4 inch openings, from 6 to 360 N·m
- Sizes with * in torque length require a target torque setting calculation
- Suitable for 7465, 74W9, 74W14, 74P9, 74P14, IZO-D, TAW9, TAW14, TAWM9, TAWM14 wrenches

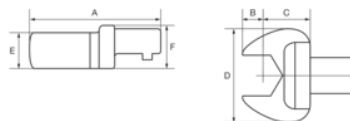

Follow the Fish!



PRODUCT ATTRIBUTES

Product				A	B	C	D	E	F	
147-1.1/4	1 1/4 in	14x18 mm	360 N·m	75 mm	17 mm	35* mm	70 mm	13 mm	20 mm	0.26 kg

