



ENGLISH

Datasheet

RS Pro 2 Way Tilt and Swivel Machine Vice

RS Stock No: 463-7319



Specifications:

Heavy duty precision milling vices with swivel and tilt base.

Used in milling, shaping and drilling machines.

Swivel base is marked 360 degrees in 1 degree divisions.

Tilt capacity 90 degrees marked in 1 degree divisions

Parallelism of sliding surface to base 0.06mm / 100mm

Parallelism of jaws 0.05mm / 100mm

Squareness of fixed and moving jaws to upper slide surface 0.05mm / 100mm

Parallelism of base of bar clamped between jaws and sitting on the upper slide surface
0.08mm / 100mm

Order Code	Manufacturers Code	Description
463-7319	52-832-100	2 Way Tilt and Swivel Machine Vice




ENGLISH

Datasheet

RS Pro 2 Way Tilt and Swivel Machine Vice

Max Jaw Opening mm	Jaw Width mm	Jaw Height mm	Angular Graduations
80	100	41	1 deg.

Fixing Bolt Size	Locating Key Width	Weight Kg
M12 x 40	14mm	16.2

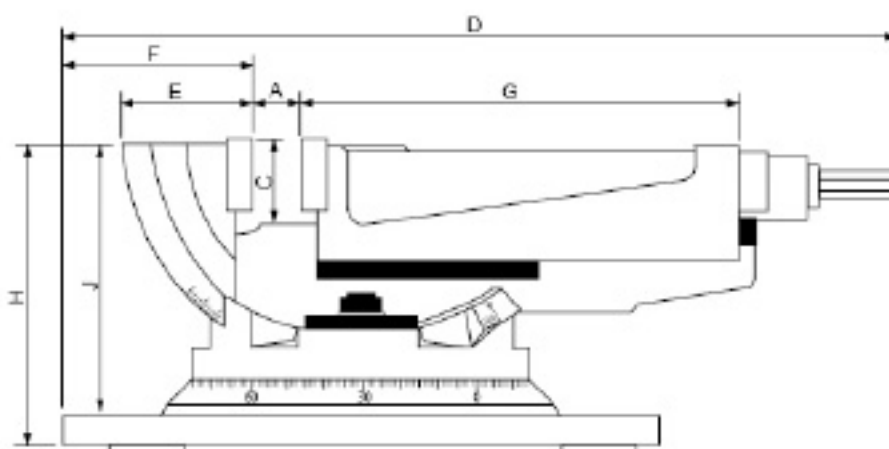

A-Max mm	B mm	C mm	D-Min mm	D-Max mm	E mm	F mm	G mm	H mm	J mm	K mm
80	100	41	312	398	58	90	162	148	133	185