




ENGLISH

Datasheet

Stock No: 403-314

RS Pro IDC Interface Module

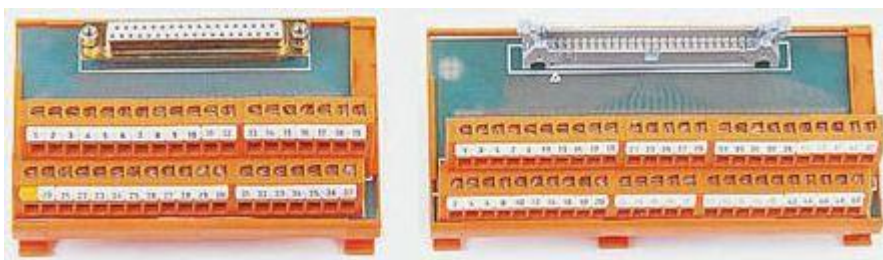

Product Details

IDC Header

Screw terminal interface modules with connectors suitable for interfacing electrical cabling to I/O cards and electronic equipment. Designed to mount on standard BS 5584:1978 & 146; DIN & 146; rail., Orange polyamide 6.6 housings with gold plated connector contacts

Temperature range -20 to +50°C

Suitable Cable CSA: (Flexible) 2.5mm², (Solid) 4 mm²



ENGLISH

Product Details

Dimensions (mm)			
Stock No.	Height	Length	Width
403-308	62	45	70
403-314	62	70	70
403-320	62	90	70
424-462	62	110	70
403-336	62	115	70
403-342	62	145	70

Interface Modules (DIN Rail Mounting)

Specifications:

Number of Contacts	20
Connector Type	IDC
Mounting Type	DIN Rail Mount
Voltage Rating	50 V
Current Rating	1A
Cable CSA	4mm ²
Dimensions	70 x 70 x 62mm
Depth	62mm
Length	70mm
Minimum Operating Temperature	-20°C
Width	70mm
Maximum Operating Temperature	+50°C