

HC-B 6-AP-GY - Cover plate

1660368

<https://www.phoenixcontact.com/gb/products/1660368>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

HEAVYCON cover plate, for wall cutouts of type B6, 3.5 mm thick, gray



Commercial data

Item number	1660368
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	AF7AZD
Product key	AF7AZD
Catalog page	Page 664 (C-2-2019)
GTIN	4017918022006
Weight per piece (including packing)	18.25 g
Weight per piece (excluding packing)	17.965 g
Customs tariff number	39269097
Country of origin	DE

HC-B 6-AP-GY - Cover plate

1660368

<https://www.phoenixcontact.com/gb/products/1660368>



Technical data

Notes

General	For wall cutouts of type B6
---------	-----------------------------

Product properties

Product type	Cover plate
Type	B6
No. of cable outlets	3
Seal present	yes

Dimensions

Dimensional drawing	
Width	52 mm
Height	4.5 mm
Length	86 mm
Drill hole distance, horizontal	70 mm
Drill hole distance, vertical	32 mm
Hole diameter	4.5 mm

Installation dimensions

Width of the assembly cutout	36 mm
Length of the assembly cutout	52 mm

Material specifications

Material	PA
Flammability rating according to UL 94	HB
Seal material	PTS

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP54
Ambient temperature (operation)	-20 °C ... 100 °C


HC-B 6-AP-GY - Cover plate

1660368

<https://www.phoenixcontact.com/gb/products/1660368>



Drawings

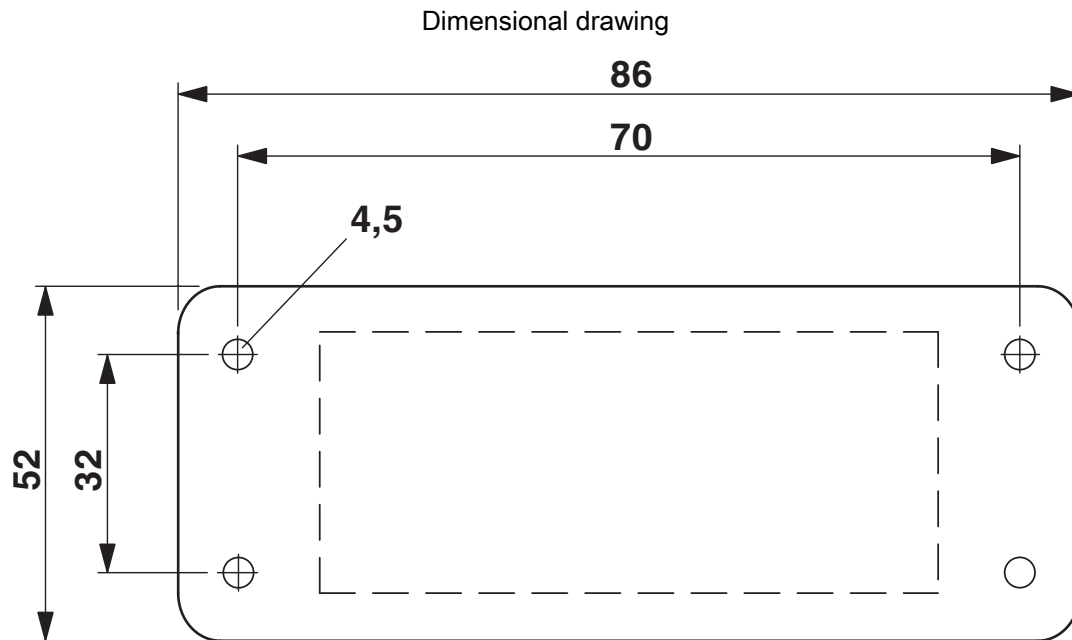

Dimensional drawing

HC-B 6-AP-GY - Cover plate

1660368

<https://www.phoenixcontact.com/gb/products/1660368>



Classifications

ECLASS

ECLASS-13.0	27440201
-------------	----------

ETIM

ETIM 9.0	EC002309
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

HC-B 6-AP-GY - Cover plate

1660368

<https://www.phoenixcontact.com/gb/products/1660368>



Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd
Halesfield 13, Telford
Shropshire, TF7 4PG
01952 681700
info@phoenixcontact.co.uk