


# IT master-slave PRO socket strip 5-fold (type G)

Item-no.: 0214x0605834b-1 (1,5 m cord)

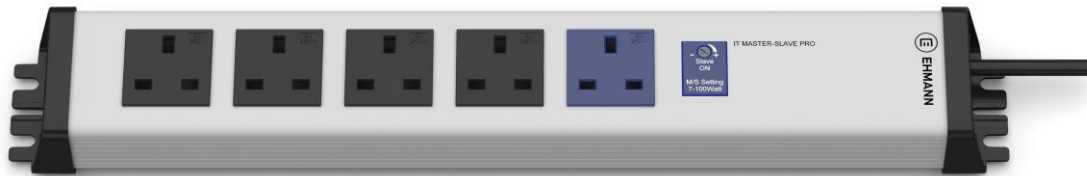

Robust plastic, grey

Built-in sockets (90° rotated), quadrangular


1,5 m power cord and angle plug

Automatic electronic switching M/S with precisely adjustable switching threshold

Optical function display for M/S function


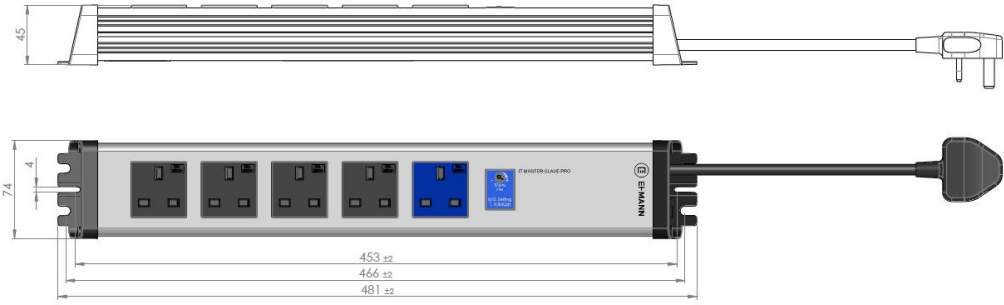
Expanded contact protection by using a shutter

End caps with mounting possibility (19")

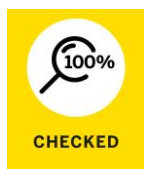

## IT master-slave PRO socket strip 5-fold (type G)

### Technical data

<p><b>3.600 W</b> <b>Power</b></p>	<p><b>230 V ~ (+/- 10%) / 50 Hz</b> <b>Rated voltage</b></p>	<p><b>16 A</b> <b>Rated current</b></p>
<p>Power Cord: H05VV-F 3G 1,5 mm<sup>2</sup>            Plug: BP1 British Standard Type G, BS 1363/A, angled            Sockets: Type G            Precise switching threshold: 7-100 W (master)            Consumption: &lt; 0,6 W            Safety class: IP20</p>		
 <p>(similar illustration)</p>		
<p>Item-no. 0214x0605834b-1 (1,5 m cord)    EAN4012096013495    PU 10</p>		<p>481 x 74 x 45 mm Dimensions (L x W x H) 453 mm Fixing dimension</p>