

# Ratcheting Combination Wrenches

The producers of the World famous Crescent® adjustable wrench now offer you two new styles of ratcheting wrenches: the *REVERSIBLE* Ratcheting Combination Wrench (works where other wrenches won't), and the Ratcheting Combination Wrench (the simplicity of a combination wrench with the speed of a ratchet). The open end jaw surfaces are parallel to within  $\pm 0.0015"$  for better contact with fastener surfaces and higher torque transfer. All two styles feature mirror finished chrome vanadium steel construction for maximum strength, durability, and corrosion resistance. The narrow cross-section design on box and open ends allows access to tighter work spaces, making the wrench more versatile.

**Packaging that shows and sells:**

Every set of Crescent® ratcheting combination wrenches is packaged to grab your customer's attention and immediately make him or her aware of the features and related benefits of these quality tools. All packages have a built-in "Try Me!" feature that allows the consumer to actually touch the product and to see for themselves how the Crescent reversible ratcheting wrench can do more than any combination wrench they've ever seen before.

**Four piece sets** come with a heavy duty plastic storage tray (except type FRRM4P which comes in a canvas pouch) designed to fit permanently in a tool drawer or toolbox. Trays are made of durable, heavy duty textured plastic and have custom fit cutouts that keep the wrenches organized and close at hand. Supplied on a sturdy, full colour hang card with product features and benefits shown in English, Spanish, French, German, Dutch, Italian and Swedish.



**FRRM4EU**

**Seven piece sets** come in a heavy duty open face carry case made of tough textured plastic. Wrenches rest in individual channels, held securely by a durable snap-fit closure. Case features an integral carry handle for added convenience. Product features and benefits shown in English, Spanish, French, German, Dutch, Italian and Swedish.



**FRRM7EU**

**Open stock** is packaged on a sturdy, attractive hang-up card. These serve as back-up stock to the individual parts in each set, and offers other key individual sizes not in our sets.



**FRR10**

# Ratcheting Combination Wrenches




FRM7EU



FRM4EU

- Patented ratchet feature turns bolt with just 5° handle swing compared to 30° required in standard combination wrenches.
- Closed end works in places deep sockets will not reach and the narrow cross-section allows access to tighter working spaces than other styles of ratcheting wrenches.
- Open-end jaw surfaces are parallel to within ± 0,0015" for better contact with fastener and higher torque potential.
- 72 tooth ratcheting mechanism receives special heat treat process for maximum strength. Tools exceeds ANSI torque loads for standard combination wrenches.
- Mirror finish chrome vanadium steel for maximum strength, durability, aesthetics and corrosion resistance.
- Ratcheting closed end uses 12 points of contact for less stress to the fastener.
- 4 piece set comes in a try me blistered pack tray (except type FRRM4P which comes in a canvas pouch).
- 7 piece set comes in a try me blow molded case.
- Open stock available. See pages 67 and 69.

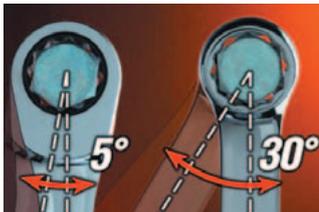

Ratchet feature turns fasteners with just a 5° swing vs. 30° needed for standard wrenches. Makes jobs go fast with its quick back and forth motion, while standard wrenches must be lifted off the bolt and repositioned with each swing.



The box end ring gear has 72 extra-fine teeth, allowing the ratchet mechanism to engage with just a 5° movement of the wrench. This important component is pre-precision machined and specially heat-treated for exceptional strength.



Works in places even deep sockets won't reach. It's the perfect tool for positioning and tightening bolts on threaded rod adjusters like those found on most electric garage door openers.



Pivot head swivels 180° for ultimate versatility. It works at any angles other flat wrenches will not handle.

Code No.	Packed	Description	Contents	Set weight g	Shelf Pack
<b>SAE</b>					
FR4*	Carded	4 Piece SAE Set	3/8", 7/16", 1/2", 9/16"	425	1
FR7*	Carded	7 Piece SAE Set	5/16", 3/8", 7/16", 1/2", 9/16", 5/8", 3/4"	1389	1
<b>Metric</b>					
FRM4EU	Carded	4 Piece Metric Set	8 mm, 10 mm, 13 mm, 15 mm	460	1
FRM7EU	Carry Case	7 Piece Metric Set	8 mm, 10 mm, 13 mm, 16 mm, 17 mm, 18 mm, 19 mm	1280	1
FRRM4P	Pouch	4 Piece Metric Set, Reversible	8 mm, 10 mm, 13 mm, 17 mm	444	1
FRPM4EU	Carded	4 Piece Metric Set, Pivot Head	8 mm, 10 mm, 13 mm, 17 mm	524	1
FRPM7EU	Carry Case	7 Piece Metric Set, Pivot Head	8 mm, 10 mm, 11 mm, 13 mm, 15 mm, 17 mm, 19 mm	1038	1

\*Discontinued, while quantity lasts