


### Deep groove ball bearings, single row, shield on both sides

Principal dimensions			Basic load ratings		Fatigue load limit $P_u$	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
6	19	6	2,34	0,95	0,04	80000	40000	0,0084	626-2Z *

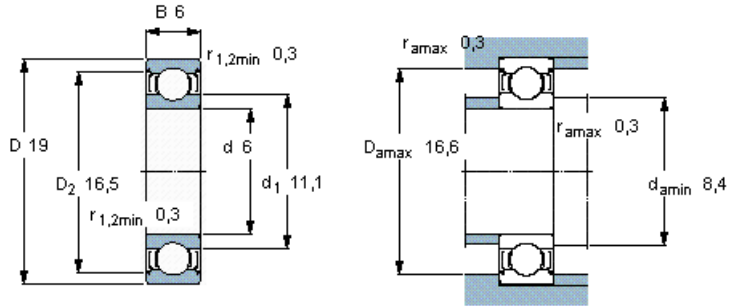

**Calculation factors**

$k_r$  0,025  
 $f_0$  13