


Universe	Professional
Type	Verticality
Category	Kits
Subcategory	Temporary horizontal lifelines and fall arrest kits

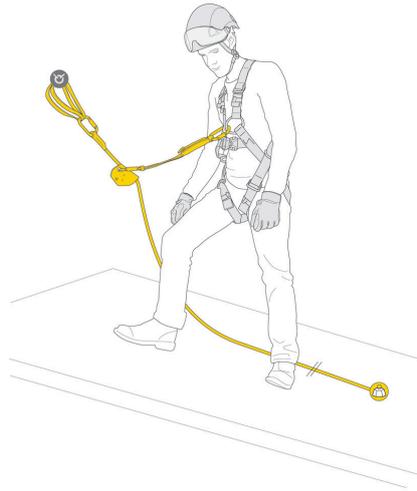

ASAP® VERTICAL LIFELINE

ASAP VERTICAL LIFELINE is a temporary vertical lifeline designed for belaying and to protect against falls from height. It contains an ASAP mobile fall arrester, an ASAP'SORBBER energy absorber, two OK TRIACT-LOCK carabiners, an ANNEAU open sling, an AXIS 11 mm rope with sewn termination, a weight, and a BUCKET bag. It is available in two lengths.

Short Description Vertical lifeline for protection against falls with ASAP mobile fall arrester

Selling Points

- Simple to use, and effective:
 - ASAP mobile fall arrester moves up or down the rope without any manual manipulation of the device
 - pre-assembled kit for a system that is ready to use and that limits the risk of assembly error
 - weight facilitates rope glide in the ASAP over the first few meters
 - BUCKET bag allows the kit to be stored and its contents identified
- Vertical lifeline contents:
 - an ASAP mobile fall arrester (European version)
 - a 40-cm ASAP'SORBBER energy absorber (European version)
 - two OK TRIACT-LOCK carabiners
 - an ANNEAU 150 cm open sling
 - an AXIS 11 mm rope with sewn termination
 - a weight
 - a 25-liter BUCKET bag
- Available in two rope lengths (10 and 20 meters)

Specification

Specifications by reference

Reference(s)	K091AA00	K091AA01
Length	10 m	20 m
Weight	2325 g	3125 g
Made in	FR	FR
Guarantee	3 years	3 years
Packing	1	1
Case quantity	1	1
EAN	3342540822061	3342540822078

Related product(s) VERTEX® BEST
VOLT®