



22MM PLASTIC ROUND COMPLETE UNIT
COMBINATION: ACOUSTIC SIGNALING DEVICE
CONTINUOUS TONE 2.4KHZ,
IP65 SOUND PRESS. MIN. 80 DB./10CM,
WITH LAMP HOLDER BA 9S 115V AC/DC SCREW
TERMINAL WITH HOLDER BLACK

Actuator:

Design of the operating mechanism

acoustic signal device

Front ring:

Product component / front ring

No

Color / of the front ring

black

Enclosure:

Shape / of the housing front

round

material / of the housing

plastic

General technical details:

Number of control points

0

Design of the acoustic signal type

continuous tone

Type of voltage

- of the operating voltage
- of the supply voltage
- of the acoustic signal element

AC/DC

AC/DC

Operating voltage / rated value

- minimum
- maximum

V

5

V

400

Supply voltage / 1		
• of the acoustic signal element		
• at 60 Hz / for AC / rated value	V	115
• at 50 Hz / for AC / rated value	V	115
• for DC / rated value	V	115
Design of the electrical connection		
		screw-type terminals
Number of switching positions		
		0
Product extension / optional / fluorescent materials		
		Yes
Resistance against shock		
• for devices with incandescent lamp / according to IEC 60068-2-27		<= 30g
• for devices without incandescent lamp / according to IEC 60068-2-27		<= 50g
Resistance against vibration / according to IEC 60068-2-6		
		20 ... 200 Hz: 5g
Operating cycles / maximum		
	1/h	1,000
Item designation		
• according to DIN EN 61346-2		P
• according to DIN 40719 extendable after IEC 204-2 / according to IEC 750		H

Auxiliary circuit:

Number of NC contacts / for auxiliary contacts		
		0
Number of NO contacts / for auxiliary contacts		
		0
Number of change-over switches / for auxiliary contacts		
		0

Installation/mounting/dimensions:

Type of mounting		
		front mounting
Shape / of the installation hole		
		round
Installation width		
	mm	28
Mounting diameter		
	mm	22
Mounting height		
	mm	10
Tightening torque / of the screws in the bracket / maximum		
	N·m	1

Ambient conditions:

Ambient temperature		
• during operating	°C	-25 ... 70
• during storage	°C	-40 ... 80
Protection class IP		
		IP65

Certificates/approvals:

General Product Approval



CQC



CSA

[ROSTEST](#)



UL

Test Certificates

[Manufacturer](#)

Shipping Approval



ABS



BUREAU
VERITAS



DNV



LRS



PRS



RINA

other

[Manufacturer](#)

Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/industrial-controls/mall>

CAX-Online-Generator


<http://www.siemens.com/cax>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/3SB3234-7BA10/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3SB3234-7BA10

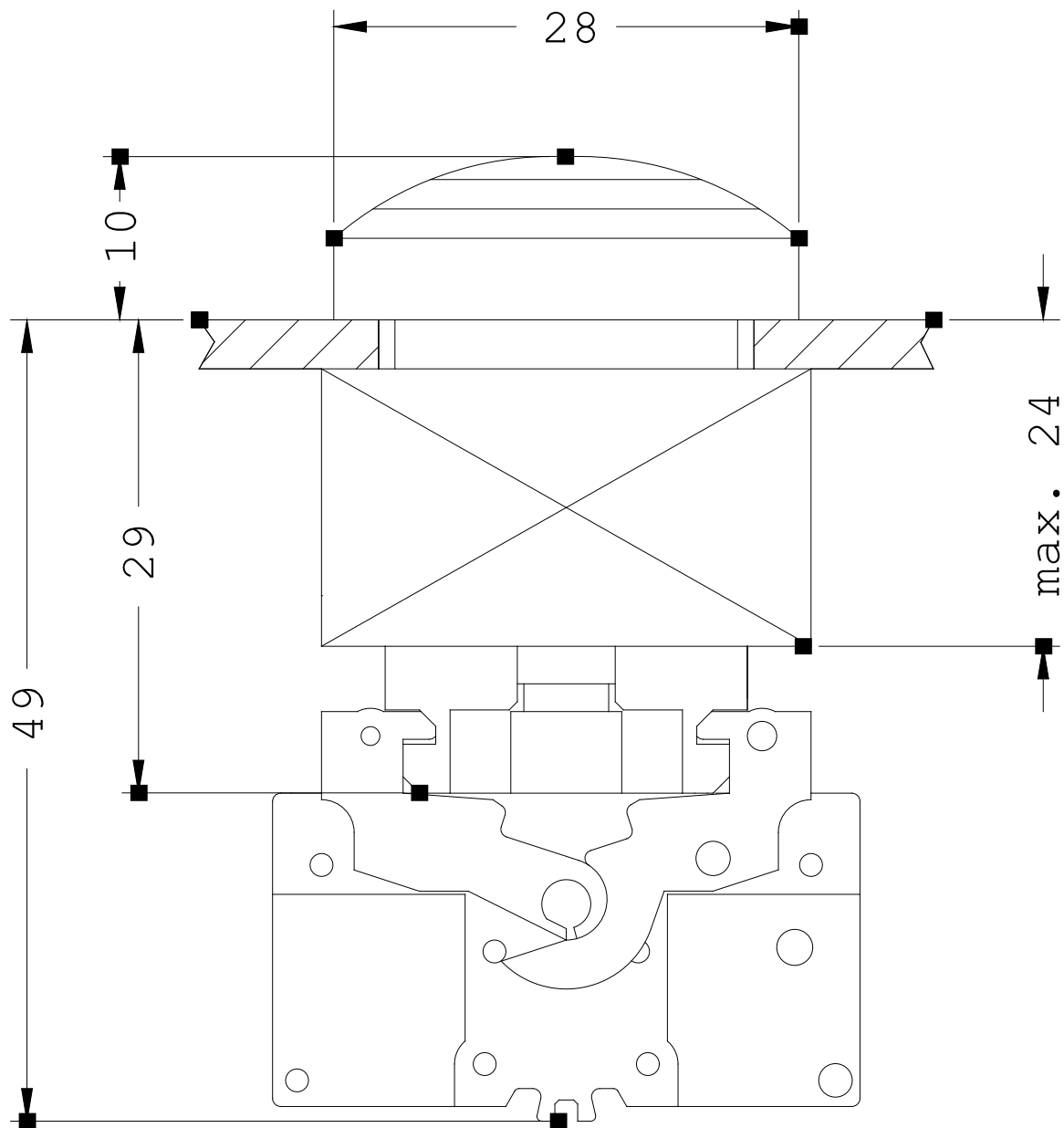

last change:

Oct 31, 2011