


ENCLOSED HOSE REELS FOR COMPRESSED AIR / STEEL

DGF Series - Large industrial type - Rubber hose



Part number	Length (m)	Flow rate (l/min)	Temperature min/max (°C)	Max. operating pressure (bar)	Net weight (Kg)	Male thread	Female thread	Profile
DGF 0810ES	10.00	500.00	-15.00 / 40.00	12.00	15,446		G3/8	EUROPEAN
DGF 0815ES	15.00	350.00	-15.00 / 40.00	12.00	16,446		G3/8	EUROPEAN
DGF 0820ES	20.00	260.00	-15.00 / 40.00	12.00	17,186		G3/8	EUROPEAN
DGF 1010ES	10.00	900.00	-15.00 / 40.00	12.00	15,436		G3/8	EUROPEAN
DGF 1015ES	15.00	700.00	-15.00 / 40.00	12.00	16,486		G3/8	EUROPEAN
DGF 1310ES	10.00	1800.00	-15.00 / 40.00	12.00	17,4	G1/2		EUROPEAN
DGF 0815BS	15.00	350.00	-15.00 / 40.00	12.00	16,446		G3/8	BRITISH
DGF 0820BS	20.00	260.00	-15.00 / 40.00	12.00	17,186		G3/8	BRITISH

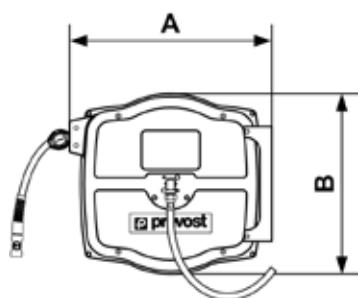

Part number	Dim. A (mm)	Dim. B (mm)	Ø int/ext (mm)
DGF 0810ES	520.00	462.00	8.00 / 14.00
DGF 0815ES	520.00	462.00	8.00 / 14.00
DGF 0820ES	520.00	462.00	8.00 / 14.00
DGF 1010ES	520.00	462.00	10.00 / 17.00
DGF 1015ES	520.00	462.00	10.00 / 17.00
DGF 1310ES	520.00	462.00	13.00 / 20.00
DGF 0815BS	520.00	462.00	8.00 / 14.00
DGF 0820BS	520.00	462.00	8.00 / 14.00