

## Features

- Maximum operating pressure is 12 bar.
- Operating temperature range -20°C to +100°C.
- Material: Brass / Aluminum /Steel Nickel & Zinc Plated Finish
- Single Shut Off (One side is with valve)
- DN8
- ISO 4414
- ISO 6150-B-15
- Industrial Interchangeable 3/8"
- 2-Stage Safety Coupling
- Compatible with:  
HANSEN 4000  
PARKER 30 3/8"  
CEJN 430  
GROMELLE 900  
RECTUS 30

## RS PRO Pneumatic Quick Connect Coupling

RS Stock No.: 0325635



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

### RS PRO Series 30S Quick Connect Couplings

Pneumatic quick-connect coupling connectors are found across industry in pneumatic systems as diverse as robotic assembly lines and other equipment.


2-Stage Security: Security is provided by pressing the button two times or by left-right sleeve twist. First press/twist releases the pressure inside the coupling and the second press/twist ejects the plug for disconnection.

- Maximum operating pressure is 12 bar.
- Operating temperature range -20°C to +100°C.
- Material: Brass / Aluminium /Steel Nickel & Zinc Plated Finish
- Single Shut Off (One side is with valve)
- DN8
- ISO 4414
- ISO 6150-B-15
- Industrial Interchangeable 3/8"
- 2-Stage Security
- Compatible with: HANSEN 4000 | PARKER 30 3/8" | CEJN 430 | GROMELLE 900 | RECTUS 30


## Specifications

Manufacturer Series	030S
Coupling Type	Quick Connect Coupling Socket
Connection Standard	DN 8, ISO 4414, ISO 6150-B-15, Industrial Interchangeable 3/8"
Connection Standard Compatible With	HANSEN 4000; PARKER 30 3/8"; CEJN 430; GROMELLE 900; RECTUS 30
Minimum Operating Temperature	-20°C
Maximum Operating Temperature	+100°C
Maximum Operating Pressure	12bar
Flow	2-Stage, ISO 4414
Flow Direction & Sealing	Self-sealing coupling
Material	Brass, Aluminium
Finish	Nickel Plated
Connection Type	Hose Barb
Thread Size	N/A
Thread Standard	N/A
Thread Gender	N/A
Coupling Gender	Female
Threaded Connection	N/A
Seal material	Nitrile Rubber
Hose Barb Connection	8mm

## Specifications

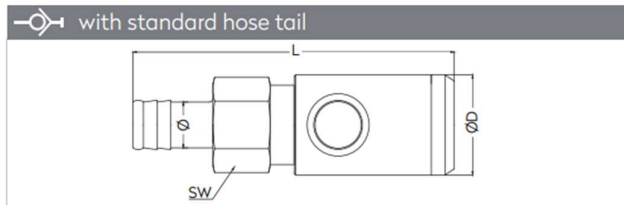

Dimensions (mm)		
SW	L	ØD
25	92.7	29

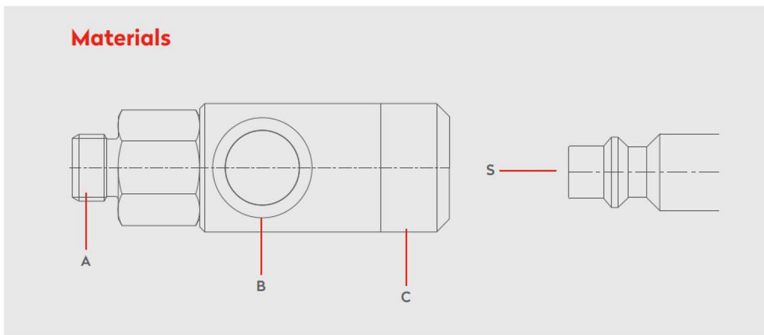

### Material Code

A = Brass Nickel Plated

B = Zinc Plated

C = Aluminium

S = Steel Nickel Plated

## Series 30S Quick Connect Couplings

	0 - 12 bar (0-174 PSI)		-20° to +100°C (NBR) -4° to +212°F	<b>Shut Off Type</b>	
	OM 138 - 01160 OM 178 - 01082 OM 178 - 00765	<b>2 - STAGE</b>	<b>ISO 4414</b>	<b>DN</b>	<b>8 mm</b>