

Products

Micro Speaker

Micro Speaker

Micro Speaker

KDSG20008

PRINT


Shape

KDSG20008




Rated Input(W)	0.08
Maximum Input(W)	0.2
Impedance(?)	8±15%@1.0KHz 1.0V
Rated Frequency (Hz)	750±20%@1.0V
Sound Pressure Level (dB)	86±3dB(0.08w/10cm),76 ±3dB(1w/1m)
Frequency Range (Hz)	Fo--5K
Magnet (mm)	ϕ.5x1.5 Nd-Fe-B
Operating Temperature (?)	-20~+55
Weight (Gram)	2.3
Material	ABS UL-94 1/16" HB

Dimension

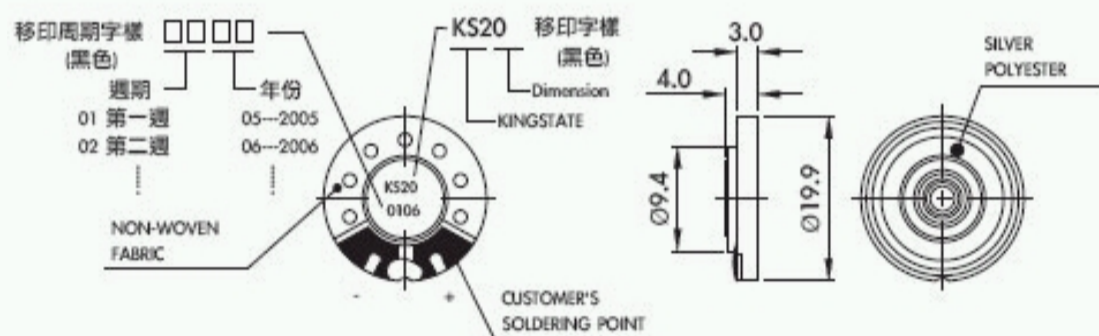

Characteristic / Schematic Diagram

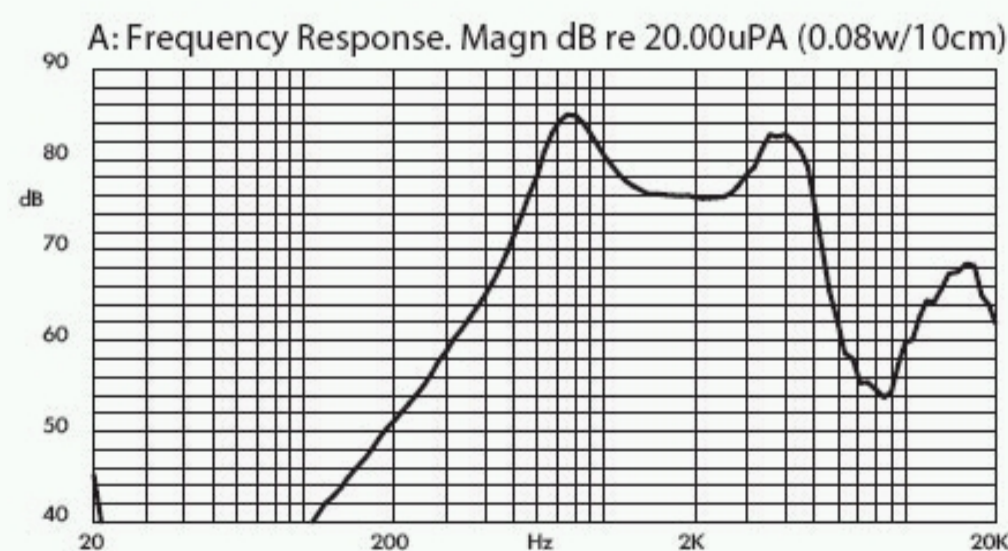

Back

TOP

Part Number Search

Hot Product



High SNR Microphone

ϕ10*4.5

[More info](#)



Array Microphone

24 x 8 x 2.8

[More info](#)

NEWS

▶ ? electronica 2010 ?
 Hall B6, Booth
 No.118 **NEW** ..[More info](#)

▶ ? TAITRONICS
 2010? Taipei World
 Trade Center
 Nangang Exhibition
 Hall,Booth
 No.L1019/1021 **NEW**
 ..[More info](#)

▶ KINGSTATE Ultra-
 Thin ESL Speaker
 and Danish AM3D
 Audio Software Demo
 Event Successfully
 Held On May 12,
 2010 **NEW** ..[More info](#)