




UBOOT10/15-NI-KIT

Ruland UBOOT10/15-NI-KIT, Universal Joint Boot for 0.620" (15.75mm) OD, Nitrile, Single Bellows

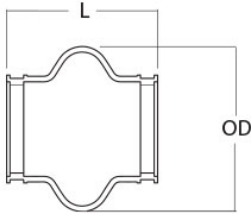

Description

Ruland UBOOT10/15-NI-KIT is a Nitrile boot cover kit for universal joints with an OD of 0.620" or 15.75mm. This boot cover protects the universal joint from unwanted contaminants such as dust and can be packed with grease for lubrication retention reducing maintenance and extending joint life. It comes with zip ties that seat into grooves on each yoke ensuring a tight seal. UBOOT10/15-NI-KIT is made from Nitrile for durability and abrasion resistance that helps protect the boot from being damaged and grease leaking out or contaminants entering the joint. Nitrile also has high resistance to petroleum-based oils and fuels, silicone greases, hydraulic fluids, water, and alcohol which are commonly present in operating environments where this universal joint is used. It is designed to fit with single and double universal joints beginning with US10, USSK10, USS10, UD10, UDSK10, UDS10, MUS15, and MUSSK15.

Product Specifications

Boot Outer Diameter (OD)	1.13 in (28.7 mm)	Length (L)	1.030 in (26.2mm)
Bellows	Single	Material Specification	Nitrile
Manufacturer	Belden Universal	Country of Origin	USA
Weight (lbs)	0.005000	UPC	634529289327
Tariff Code	8483.60.4000	UNSPC	25173810
Note 1	Performance ratings are for guidance only. The user must determine suitability for a particular application.		