

All MULTILOCK, RECEPTACLE AND TAB (81)

Product Compliance


For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts

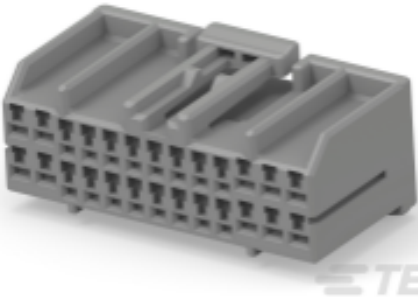


TE Part # 917994-6
HYBRID MK-2 PLUG HSG ASSY 26P

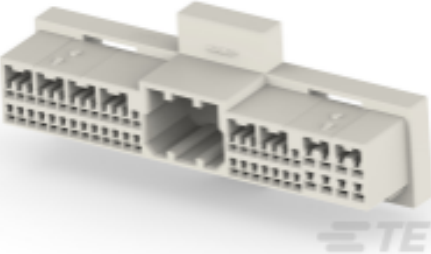


TE Part # 177698-1
IMPUL MATE PLUG HSG ASSY 48P

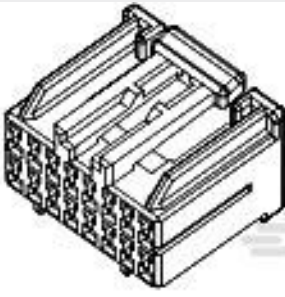


TE Part # 917992-2
HYBRID MK-2 PLUG HSG ASSY 26P

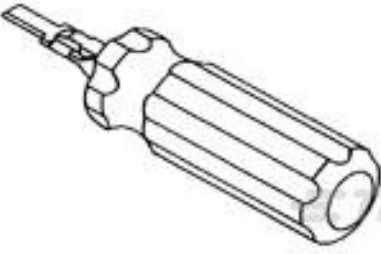

TE Part # 715131-1
EXTRACTION TOOL

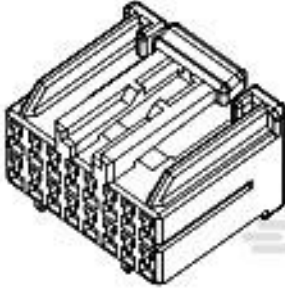


TE Part # 917981-6
HYBRID MK-2 PLUG HSG ASSY 16P

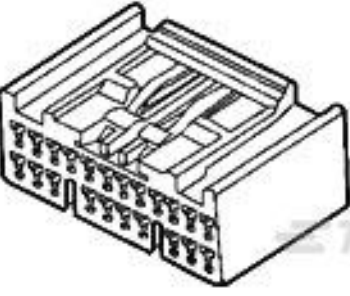

TE Part # 179620-7
AIR BAG PLUG HSG ASSY 22P



TE Part # 917850-2
HYBRID MK-2 PLUG HSG ASSY 26P

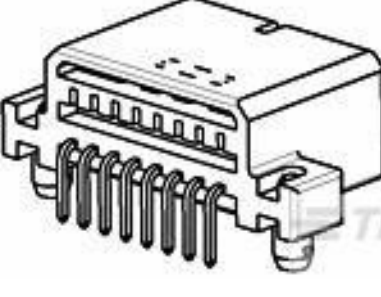

TE Part # 9-638973-2
ASSY, 8POSN CAP .040MULT/CPA



TE Part # 1438759-2
22Way Hybrid 040/2.8 Plug Assy Key "C"




TE Part # 2305570-1
Strip Terminal Cutter-Side Feed-No Crimp



TE Part # 917994-5
HYBRID MK-2 PLUG HSG ASSY 26P



TE Part # 91588-1
CCII 040 II SERIES S REC TAB 22-18 ASSY

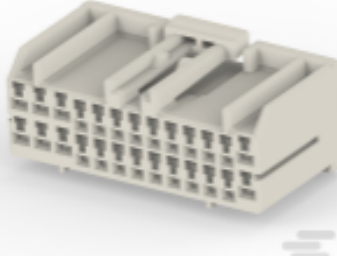

TE Part # 917997-1
HYBRID MK-2 PLUG HSG ASSY 26P




TE Part # 2151169-1
OCEAN_2.0_APPLICATOR-S-070F070F-RSM




TE Part # 2151169-2
OCEAN_2.0_APPLICATOR-S-070F070FA-RSA




TE Part # 7-2151169-7
OCEAN_2.0_SPARE_PART_KIT-070F070F

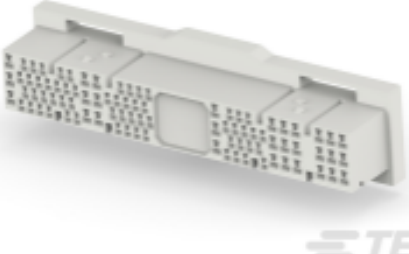


TE Part # 178080-1
IMPUL PLUG CONN 88P

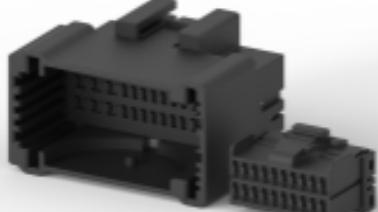

TE Part # CAT-M9194-CH8172
MULTILOCK, CONNECTOR HOUSING

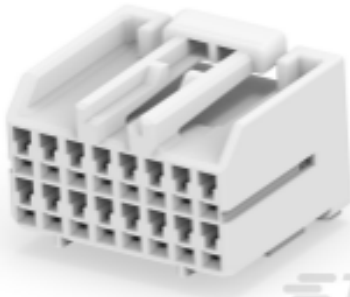

TE Part # 917983-1
HYBRID MK-2 PLUG HSG ASSY 16P

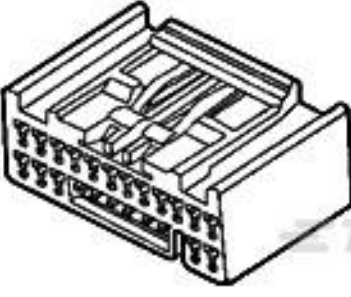


TE Part # 4-177746-5
AIR BAG PLG ASY 21P 1 S/BAR

Customers Also Bought






TE Part #11027286-00
44008RC, THERM, ROHS

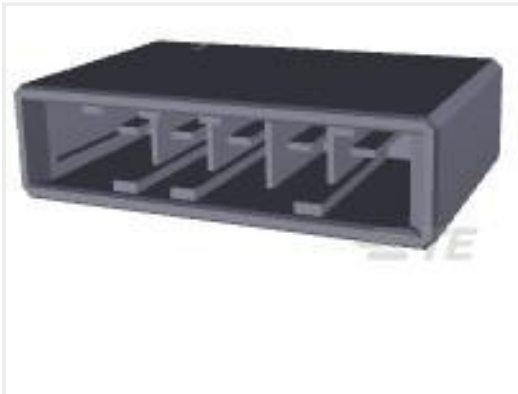

TE Part #1-316132-2
DYNAMIC D-3200 HDR ASSY 5P V

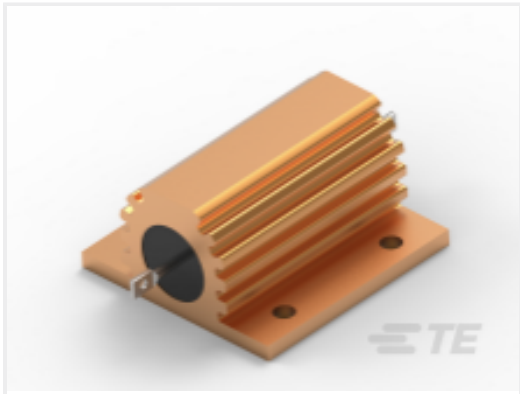

TE Part #CAT-C339-H85913
Power Resistors: Aluminum Housed, HSA



TE Part #CAT-M9194-T273
MULTILOCK, RECEPTACLE AND TAB




TE Part #4-1473562-3
RITS CONN. PLUG ASSY 3P GREEN



TE Part #T2120062201-001
HK2/4-006-F



TE Part #1-1393304-1
V23134J1053D642-EV-CBOX

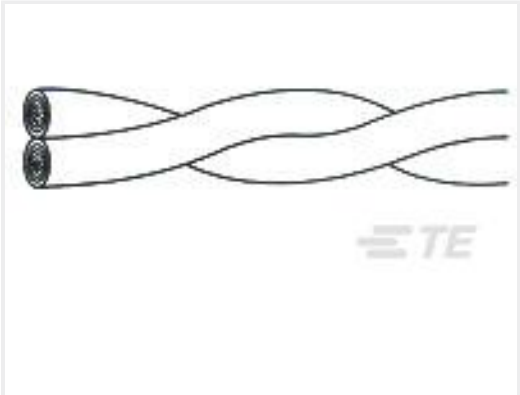

TE Part #316127-000
55A0121-20-0/9

Documents

Product Drawings

040 REC (S) FOR 100P PMC

English

CAD Files

3D PDF

English

Customer View Model

ENG_CVM_175266-2_L.2d_dxf.zip

English

Customer View Model

ENG_CVM_175266-2_L.3d_igs.zip

English

Customer View Model

ENG_CVM_175266-2_L.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

MULTILOCK Connector System

English

Product Specifications

Application Specification

English

Crimping .040II Series Tab and Rec. Contact

English

