


Safe-D Spring Clip



Can be positioned at varying angles according to space and volume requirements

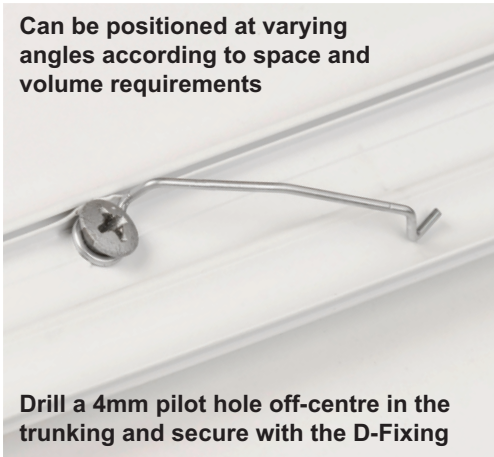

Drill a 4mm pilot hole off-centre in the trunking and secure with the D-Fixing



In 20x10mm Micro+ trunking

In traditional 16x10mm trunking


Safe-D Spring Clips effectively secure single cables (<7mm o/d), either direct to surface or in PVC micro trunkings.

Safe-D Springs use high-temperature non-corrosive sprung steel that is tensioned to provide a strong contact with trunking bases.

In fire conditions, the Springs (when secured with D-Fixings) can hold cables in-situ at 970°C for up to 2 hours. They satisfy all requirements of BS5839 Part 1.

The 50mm long arm is specially kinked to minimise risk of cable bruising or damage to the conductors of soft-skin cables.

- Fully safety tested, for compliance with BS7671 and BS5839 part 1
- >1200°C melting point
- Non-corrosive finish
- Fixing hole is ideal for use with D-Fixings
- Perfect for securing cables in micro trunkings, or direct-to-surface
- Can be fixed on surfaces at any angle to hold a variety of cable options

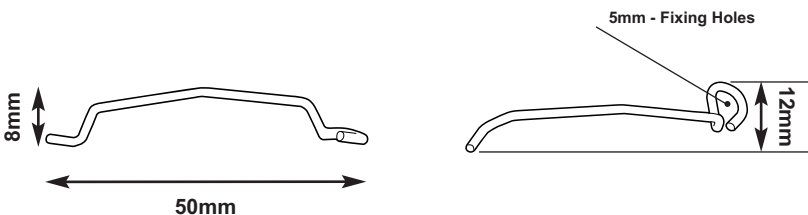

Code	Description
1823864	(L) 50mm x (W) 12mm x (H) 8mm 5mm diameter fixing hole