



10115019

pitch 5/8in x 3/8in - Chain sprockets ASA

2D Technical Drawing

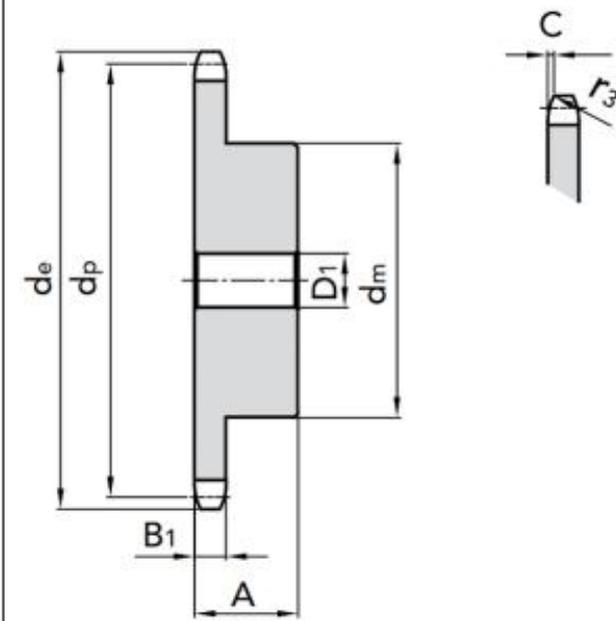

 Dynamic 3D View



Technical Specifications

Number of teeth (T)	19
de (DE) mm	103.30
dp (DP) mm	96.45
Part number (CODE)	10115019
dm (DM) mm	70
D1 (D1) mm	14
A (A) mm	30
Tooth radius r3 (R3) mm	17
Radius width C (C) mm	2
Sprockets tooth width B1 (B1) mm	9
Weight (WEIGHT) kg	1.15
Material (MAT)	STEEL C45