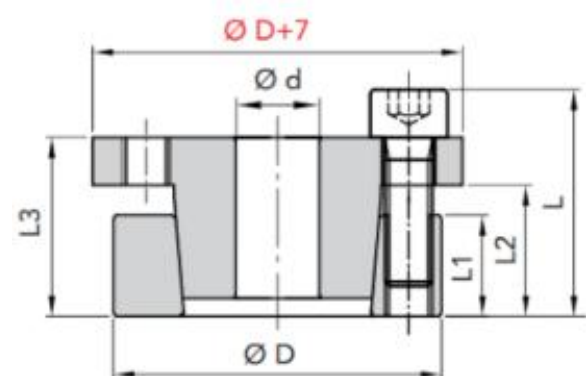


06151040

RCK 15 - Self centring

2D Technical Drawing

Dynamic 3D View
Technical Specifications

Part number (CODE)	06151040
Ød (DD) mm	40
ØD (D) mm	65
L1 (L1) mm	17
L2 (L2) mm	22
L3 (L3) mm	31
L (L) mm	39
Maximum torque Mt (MT) Nm	1030
Clamping pressure - Shaft (CPS) N/mm ²	200
Clamping pressure - Hub (CPH) N/mm ²	122
Clamping screws DIN 912 MAT. 12.9 - Num. (CSN)	5
Clamping screws DIN 912 MAT. 12.9 - Type (CST)	M8x25
Clamping screws DIN 912 MAT. 12.9 - Torque (CSTQ) Nm	41
Extraction thread - Type (ETT)	M8
Extraction thread - Num. (ETN)	3
Weight (WEIGHT) kg	0.50