


# THERMOELEMENT ROHRSCHELLE

Kunststoffindustrie

**PT COLLIER / SCI**

THERMOELEMENT

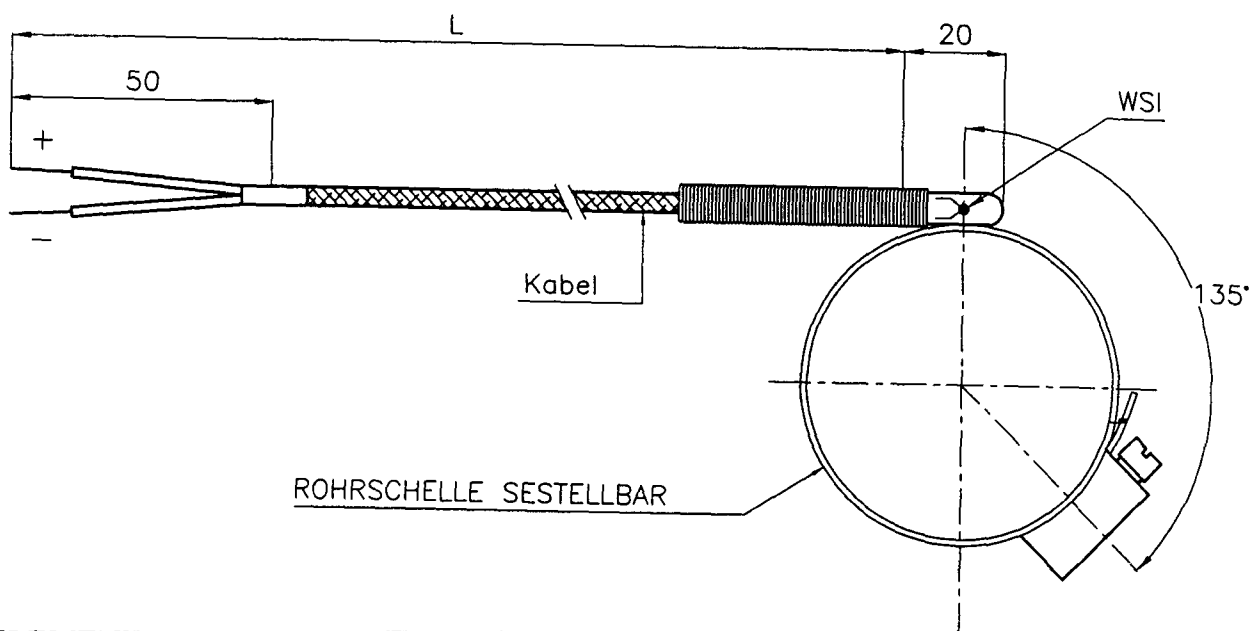

**MESS-ELEMENT**

: Thermoelement J 0 +600°C  
Nach IEC

**WARME SCHWEISSUNG**

: Isoliert

**BEFESTIGUNG**

: Rohrschelle sestellbar ron Ø14 bis 82 mm

**KABEL**

: Mehradrig biegsam – 7x0,20  
Isolierstoff glass-seide / Glass-seide / Inox flechte

**BESTELL NUMMER**

:

	L = 2000mm	L = 3000mm	L = 4000mm
Ø14 - 22	PT/COLLIER/SCI/14/2000	PT/COLLIER/SCI/14/3000	PT/COLLIER/SCI/14/4000
Ø24 - 36	PT/COLLIER/SCI/24/2000	PT/COLLIER/SCI/24/3000	PT/COLLIER/SCI/24/4000
Ø32 - 52	PT/COLLIER/SCI/32/2000	PT/COLLIER/SCI/32/3000	PT/COLLIER/SCI/32/4000
Ø47 - 67	PT/COLLIER/SCI/47/2000	PT/COLLIER/SCI/47/3000	PT/COLLIER/SCI/47/4000
Ø62 - 82	PT/COLLIER/SCI/62/2000	PT/COLLIER/SCI/62/3000	PT/COLLIER/SCI/62/4000

**OPTION**

: Anders länge L = 5000 und 6000mm  
Thermoelement K oder T

FCD 067-7/97-1

**CORREGE**  
TEMPERATURE

R.N. 13 - CHAINES - B.P. 55 - F - 27120 PACY-SUR-EURE

Tel. : 02 32 26 26 00  
Tel. int. : 33 232 26 26 00

Fax : 02 32 36 40 72  
Fax int. : 33 232 36 40 72