


## Features

- 3999 Counts Smart Multimeter
- Voltage Measurement up to 600V AC/ DC
- Current Measurement up to 10A AC/ DC (Model Dependent)
- Resistance Measurement up to 40MΩ
- Non-contact Voltage Detect (NCV)
- LIVE Test
- Mis-plug Alarm
- LIVE Test
- Diode Test
- Continuity & Buzzer Indication
- Auto Hold/Power Off
- Overload Protection
- Low Battery Indication
- Backlight/ Torch
- Battery 1.5V AAA x 2/ Li-battery (Model Dependent)

## RS PRO Digital Multimeters

RS Stock No.: 296613

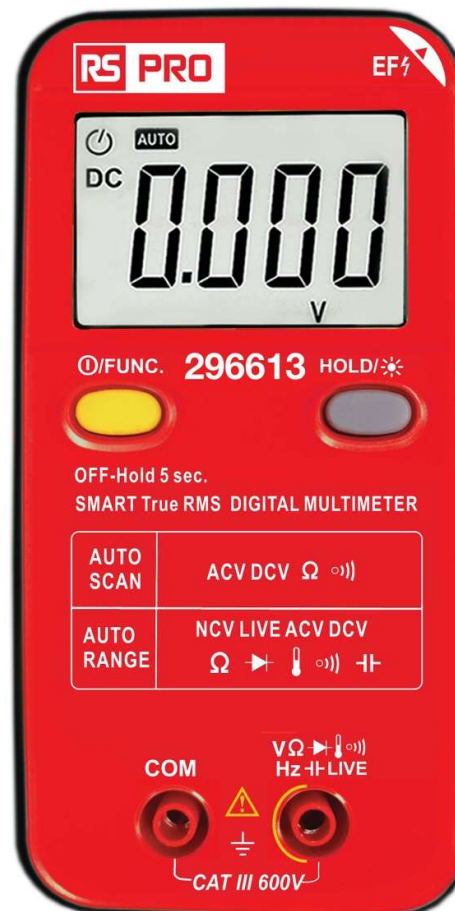

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

**296613** Pocket Size **Smart** Digital Multimeter series is a handheld device which can auto scan voltage, electrical current, resistance and continuity. Can also measure capacitance, diode and temperature with features a torch and NCV (Non-contact voltage). 296613 TRMS digital multimeter that ensures accurate results even when testing on irregular AC circuits.





## General Specifications

Function	Value
Electrical protection class	CAT III 600 V
Pollution degree	2
Operating altitude	< 2000 m
Operating temperature/ humidity	0~40°C, 32°F~104°F (<80% RH, <10°C non-condensing)
Storage temperature/ humidity	-10~60°C, 14°F~140°F (<70% RH, battery removed)
Typical temperature coefficient	0.1 x (specified accuracy) / °C (<18°C or >28°C)
Low battery indicator	The "Low Battery Indicator" is displayed when the battery is under the proper operation range
EMC	EN 61326-1
Safety LVD	EN 61010-1 EN 61010-031 EN 61010-033
Fuse	1A model:F 1A/ 600V ø6x30 (Quick Acting) 10A model:F 10A/ 600V ø6x30 (Quick Acting)
Power supply	AAA x 2 Pieces
Dimension/ weight	130(L) x 63(W) x 28(H) mm/ Approx 120g (without battery)

## Pocket Multimeter Selection Guide

	<b>296613</b>
<b>Auto Range</b>	ACV/ DCV/ Resistance/Continuity/ Diode/ Temperature/Capacitance/ NCV/ LIVE
<b>Auto Scan</b>	V/ R/ CONT/ A
<b>DC Voltage</b>	4V/ 40V/ 400V/ 600V
<b>AC Voltage</b>	4V/ 40V/ 400V/ 600V
<b>Resistance</b>	400Ω/ 4kΩ/ 40kΩ/ 400kΩ/ 4MΩ/ 40MΩ
<b>Capacitance</b>	4nF/ 40nF/ 400nF/ 4μF/ 40μF/ 400μF/ 4mF
<b>Frequency</b>	40Hz/ 400Hz/ 4kHz
<b>Temperature</b>	-200°C~1200°C±(2.0%+3)
<b>Display Counts</b>	3999
<b>LCD Size</b>	44*30 mm
<b>Safety Rating</b>	CAT III 600V
<b>Power</b>	1.5V battery (AAA) x 2
<b>Size</b>	130 x 63 x 28 mm
<b>Weight</b>	~120g (without battery)

## Panel and Constructure

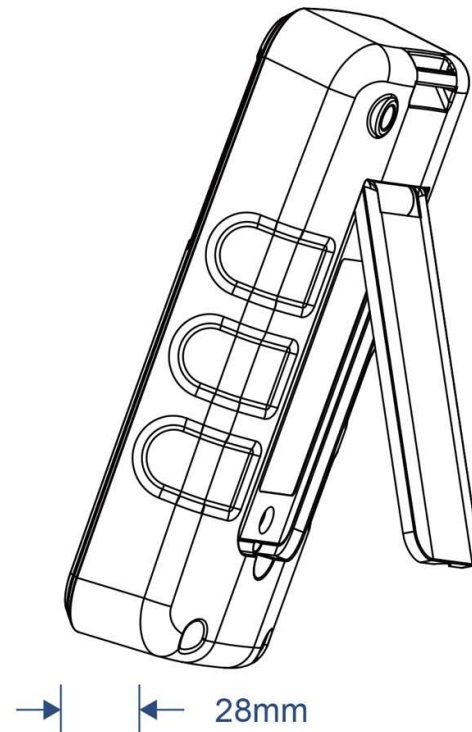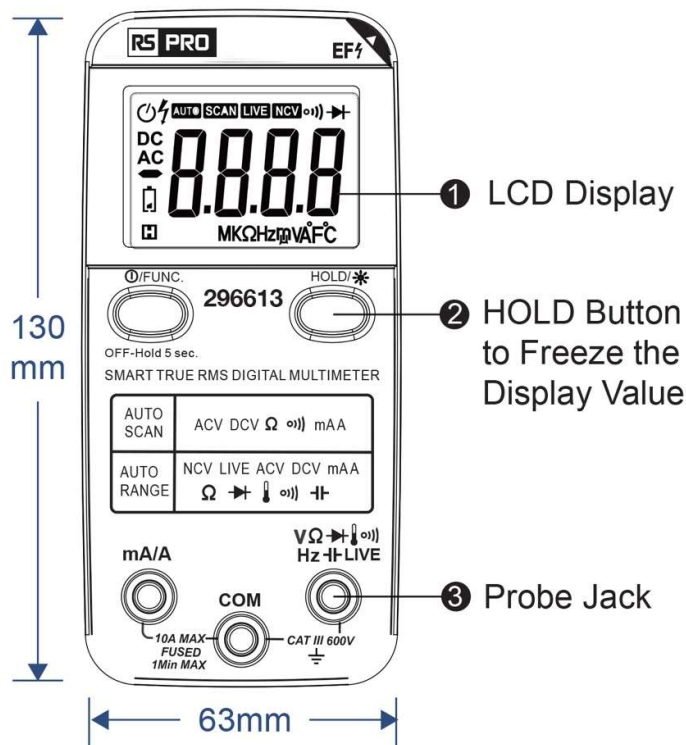

## LCD and Symbol



- Display/ char. height: 7-segment characters/ 17 mm
- Number of digits: 33/4 / 1999 steps
- Overflow display: "OL" is displayed
- Polarity display: "-" (minus sign) is displayed if plus pole is connected to "1"
- Sample rate: 3 times/ sec for digital data

## Contents



L130 x W63 x D28mm  
L5.1''x W2.5''x D1.1''  
138g/ 0.30lb



1.5V Battery  
)AAA\* x 2



Accessories

Test Leads  
K-type Thermocouple  
Battery



User  
Manual

## Packaging Information

 



Box  
L 153 X W 105 X H 40mm


## Main Applications




Domestic

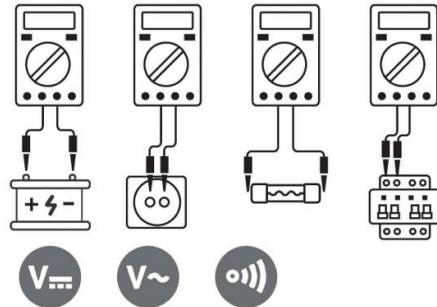

Industrial

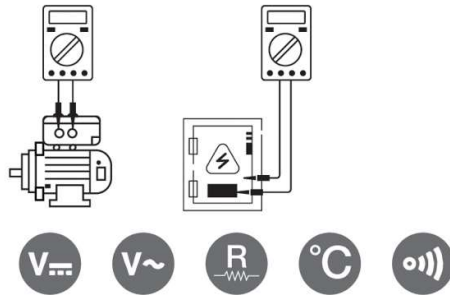

Electronics

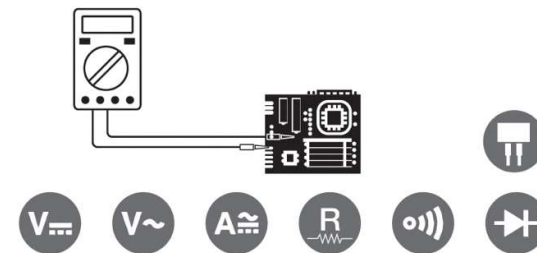

## Order Details

Stock No.	Brand	Product Name	Multimeter Type	Functions Measured	Digit Resolution
296613	RS Pro	Smart Pocket Size Digital Multimeters	Handheld	600V AC/D, $\Omega$ , CAP, Hz, $^{\circ}\text{C}$	-