

SPIRAL Series

NEW

Product Information

- Long lamp life.
- Lightweight and compact design.
- Manufactured from recyclable and environmentally friendly materials.
- Alternative to incandescent bulbs.

APPLICATIONS

Table lamps, wall lamps and pendant lamps.



SPIRAL Series



SP0205




Saving (£/Year) **£7.30**
Reduced CO₂ (kg/Year) **31**

| Order Code | Lamp Base | Diameter (mm) | Length (mm) | Weight (g) |
|------------|-----------|---------------|-------------|------------|
| 202054 | E14 | 46 | 77 | 32 |
| 202052 | B22 | 46 | 76 | 32 |

5 watt 10,000 hours Standard Pack 60(10) 300 lm WARM WHITE Colour Temp

Comparison of equivalent luminous flux

SP0205
SP0208
SP0211 Incandescent

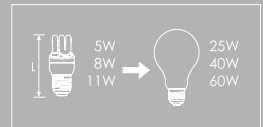

measurement based on diagonal diameter

Similar size to incandescent

lm = Lumen output



SP0208



Saving (£/Year) **£11.63**
Reduced CO₂ (kg/Year) **50**

| Order Code | Lamp Base | Diameter (mm) | Length (mm) | Weight (g) |
|------------|-----------|---------------|-------------|------------|
| 202087 | E27 | 46 | 83 | 35 |
| 202084 | E14 | 46 | 84 | 35 |
| 202082 | B22 | 46 | 80 | 35 |

8 watt 10,000 hours Standard Pack 60(10) 500 lm WARM WHITE Colour Temp



SP0211



Saving (£/Year) **£17.89**
Reduced CO₂ (kg/Year) **77**

| Order Code | Lamp Base | Diameter (mm) | Length (mm) | Weight (g) |
|------------|-----------|---------------|-------------|------------|
| 202117 | E27 | 46 | 96 | 45 |
| 202114 | E14 | 46 | 100 | 45 |
| 202112 | B22 | 46 | 93 | 45 |

11 watt 10,000 hours Standard Pack 60(10) 700 lm WARM WHITE Colour Temp



SP0214



Saving (£/Year) **£20.44**
Reduced CO₂ (kg/Year) **88**


| Order Code | Lamp Base | Diameter (mm) | Length (mm) | Weight (g) |
|------------|-----------|---------------|-------------|------------|
| 202147 | E27 | 46 | 108 | 51 |
| 202142 | B22 | 46 | 105 | 51 |

14 watt 10,000 hours Standard Pack 60(10) 900 lm WARM WHITE Colour Temp



Comparison of equivalent luminous flux

SP0214 SP0220 Incandescent

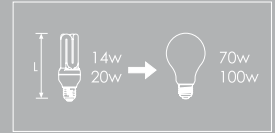

measurement based on diagonal diameter



Similar size to incandescent



SP0220



Saving (£/Year) **£29.20**
Reduced CO₂ (kg/Year) **126**

| Order Code | Lamp Base | Diameter (mm) | Length (mm) | Weight (g) |
|------------|-----------|---------------|-------------|------------|
| 202007 | E27 | 53 | 134 | 76 |
| 202002 | B22 | 53 | 132 | 76 |

20 watt 10,000 hours Standard Pack 60(10) 1350 lm WARM WHITE Colour Temp



SP0223



Saving (£/Year) **£33.58**
Reduced CO₂ (kg/Year) **144**

| Order Code | Lamp Base | Diameter (mm) | Length (mm) | Weight (g) |
|------------|-----------|---------------|-------------|------------|
| 202237 | E27 | 53 | 138 | 82 |
| 202232 | B22 | 53 | 136 | 82 |

23 watt 10,000 hours Standard Pack 60(10) 1550 lm WARM WHITE Colour Temp

