

## Features

- 19" Device Compatibility

## RS PRO Server Rack Shelves

RS Stock No.: 0749234



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

- *Racks are ideal products for ensuring the organized and secure mounting of equipment. They are commonly preferred in professional and industrial environments such as data centres, but their use may be limited in systems that require heavy load-bearing capabilities.*
- *These racks are suitable for servers, network devices, and electronic equipment, and can be integrated with other mounted accessories.*

## General Specifications

Type	2 POINT CONNECTED RACK MOUNT SHELVES
Rack Units	1U
Material	Steel
Base Material	Metal
Weight Capacity	10Kg
Rack Type	2 Point
Rack Hole Type	M6 Threads
Colour	RAL9005
Extension Type	Fixed
Paint Texture Type	Textured
Compatible Rack Size	19" Rack
Surface Finish	Electrostatic Powder Coating


## Mechanical Specifications

Dimensions	482.00mm x 300.00mm
Height	44.00mm
Width	482.00mm
Depth	300.00mm
Depth Type	Non-Adjustable
Material Thickness	1.2mm
Weight	1.37kg


## Similar Products

Stock No.	Brand	Rack Units	Material	Colour	Measurements
<b>0749232</b>	RS PRO	1U	1.2mm Steel	RAL9005	H: 44.00mm D: 200.00mm
<b>0749233</b>	RS PRO	1U	1.2mm Steel	RAL9005	H: 44.00mm D: 250.00mm
<b>0749235</b>	RS PRO	1U	1.2mm Steel	RAL9005	H: 44.00mm D: 400.00mm
<b>0749236</b>	RS PRO	2U	1.2mm Steel	RAL9005	H: 88.00mm D: 350.00mm
<b>0749237</b>	RS PRO	2U	1.2mm Steel	RAL9005	H: 88.00mm D: 550.00mm
<b>0749258</b>	RS PRO	1U	1.2mm Steel	RAL9005	H: 44.00mm D: 150.00mm


Front View

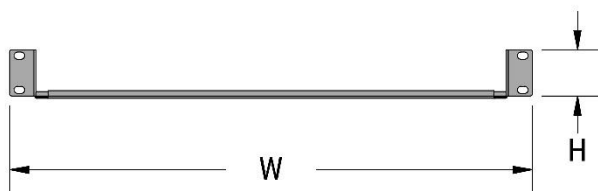

Side View

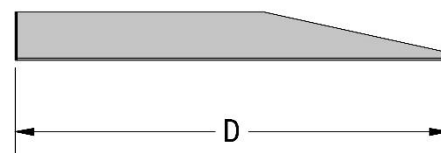

Top View

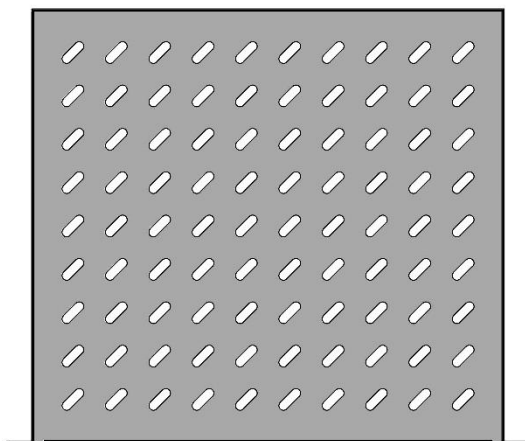

Bottom View

