


Technical data


NUTR302/3AS

Roller follower with inner ring

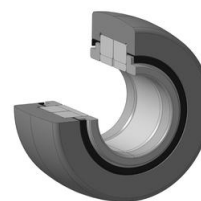

Needle roller bearing, roller follower, full-complement cylindrical roller, with inner ring, double-side shields, spherical outer ring

VISUAL (S)

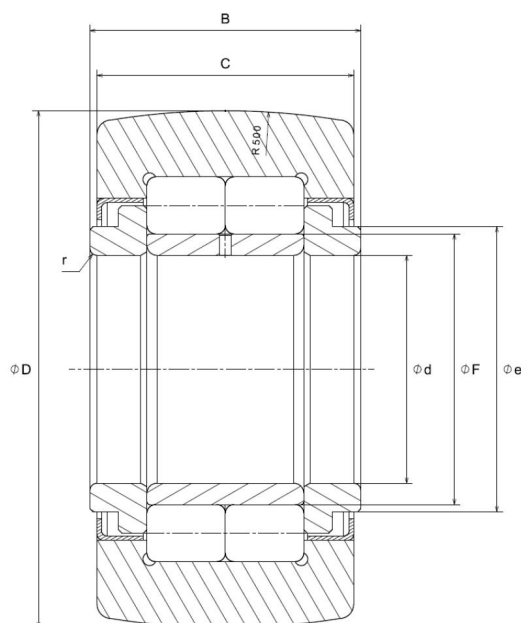

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	15 mm
D - External diameter	42 mm
C - Width of bearing, drawn cup or outer ring	18 mm
F - Under roller diameter	19 mm
B - Bearing/Inner ring width	19 mm
e - Inlet diameter of roller or washer	20 mm
R - Track roller radius	500 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION	
rs - Min fillet radius	0,3 mm
Bearing with/without cage	Sans
Radial clearance class	CN
Precision class	P0
Mass	0,16 kg

PRODUCT PERFORMANCE	
Cr - Dynamic load rating	22,3 kN
C0r - Static load rating	25,7 kN
Track load capacity spherical outer ring	4,1 kN
N lim - Grease lubrication limit speed	5500 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	120 °C

ESHOPDONOTDISPLAY	
Tracepart	Oui/Yes
Reference	NUTR302/3AS
Image	NRBNUTR_1.jpg, NRBNUTR_3.jpg
Rolling element material	Acier 100Cr6

