


CYL-9 MultiConstruction



Drilling in all kinds of materials

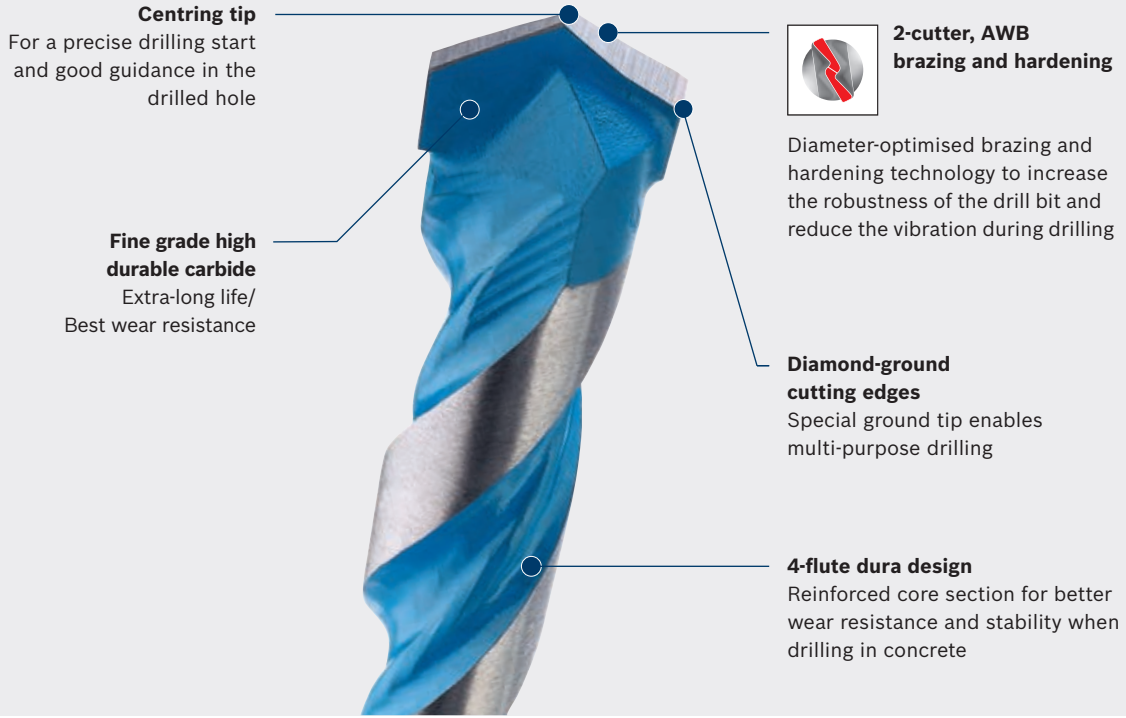

CYL-9 Multi Construction multi-purpose drill bits

- CYL-9 MultiConstruction** ▶ Suitable for practically all materials in interior fitting work, e.g. concrete, masonry, brick, eternit, light building materials, multi-layer materials, ceramics and tiles, wood, plastic, sheet metals, aluminium
- ▶ Perfect results when drilling with or without impact
- ▶ Drill bit colour: blue, polished

MULTI CONSTRUCTION

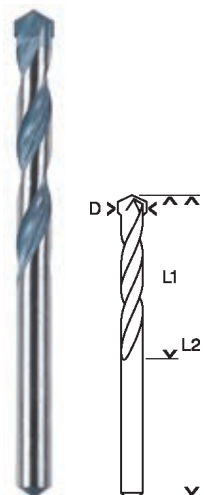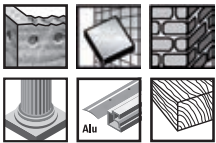

Diameter (D) mm	Working length (L1) mm	Total length (L2) mm	Part number	Packaging type	Pack quantity	Minimum order quantity	Barcode 3163140...
Product properties			Ordering information				
Pack of 1							
3.0	40	70	2 608 595 359	PC1d	1	5	328753
3.0	80	130	2 608 588 196	PC1d	1	5	693158
3.5	40	70	2 608 588 197	PC1d	1	5	693165
3.5	80	130	2 608 588 198	PC1d	1	5	693172
4.0	40	75	2 608 596 050	PC1d	1	5	044790
4.0	80	130	2 608 588 199	PC1d	1	5	693189
5.0	50	85	2 608 596 051	PC1d	1	5	044806
5.0	90	150	2 608 588 200	PC1d	1	5	693196

CYL-9 Multi Construction multi-purpose drill bits

Diameter (D) mm	Working length (L1) mm	Total length (L2) mm	Part number	Packaging type	Pack quantity	Minimum order quantity	Barcode 3165140...
-----------------	------------------------	----------------------	-------------	----------------	---------------	------------------------	--------------------

Product properties | **Ordering information**

Pack of 1


5.5	50	85	2 608 596 052	PC1d	1	5	044813
5.5	100	150	2 608 588 201	PC1d	1	5	693202
6.0	60	100	2 608 596 053	PC1d	1	5	044820
6.0	90	150	2 608 596 060	PC1d	1	5	044899
6.0	200	250	2 608 595 506	PC1d	1	1	366465
6.0	350	400	2 608 588 202	P1c	1	1	693219
6.5	60	100	2 608 596 059	PC1d	1	5	044837
6.5	90	150	2 608 596 061	PC1d	1	5	044905
6.5	200	250	2 608 595 507	PC1d	1	1	366472
7.0	60	100	2 608 596 054	PC1d	1	5	044844
7.0	90	150	2 608 596 076	PC1d	1	5	046978
7.0	200	250	2 608 595 508	PC1d	1	1	366489
8.0	80	120	2 608 596 055	PC1d	1	5	044851
8.0	90	150	2 608 585 223	PC1d	1	5	462242
8.0	200	250	2 608 596 062	PC1d	1	1	044912
8.0	350	400	2 608 595 361	P1c	1	1	328777
9.0	80	120	2 608 596 056	PC1d	1	5	044868
10.0	80	120	2 608 596 057	PC1d	1	5	044875
10.0	90	150	2 608 585 224	PC1d	1	5	462259
10.0	200	250	2 608 596 063	PC1d	1	1	044929
10.0	350	400	2 608 588 203	P1c	1	1	693226
11.0	90	150	2 608 595 360	PC1d	1	5	328760
12.0	90	150	2 608 596 058	PC1d	1	5	044882
12.0	200	250	2 608 596 064	PC1d	1	1	044936
12.0	350	400	2 608 588 204	P1c	1	1	693233
14.0	150	200	2 608 588 205	PC1d	1	1	693240
14.0	200	250	2 608 596 065	PC1d	1	1	044943
14.0	350	400	2 608 588 206	P1c	1	1	693257
16.0	150	200	2 608 588 207	P1c	1	1	693264
16.0	350	400	2 608 588 208	P1c	1	1	693271
18.0	150	200	2 608 588 209	P1c	1	1	693288
18.0	350	400	2 608 588 210	P1c	1	1	693295
20.0	150	200	2 608 588 211	P1c	1	1	693301
20.0	350	400	2 608 588 212	P1c	1	1	693318

Pack of 10

4.0	40	75	2 608 587 146	P1a	10	1	587594
5.0	50	85	2 608 587 147	P1a	10	1	587600
5.5	50	85	2 608 587 148	P1a	10	1	587617
6.0	60	100	2 608 587 149	P1a	10	1	587624
6.5	60	100	2 608 587 150	P1a	10	1	587631
7.0	60	100	2 608 587 151	P1a	10	1	587648
8.0	80	120	2 608 587 152	P1a	10	1	587655

Pack of 8

10.0	80	120	2 608 587 153	P1a	8	1	587662
------	----	-----	----------------------	-----	---	---	--------

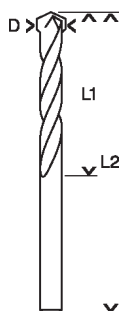

CYL-9 Multi Construction multi-purpose drill bit sets



Set size A:
156.5 x 69.5 x 23 mm

Product properties			Ordering information						
Diameter mm	Working length mm	Total length mm	Set size	Part number	Packaging type	Pack quantity	Minimum order quantity	Barcode 3165140...	
4-piece Robust Line CYL-9 Multi Construction multi-purpose drill bit set									
4.0	40	75	A	2 607 010 521	P1k	4	1	446051	
5.0	50	85							
6.0	60	100							
8.0	80	120							
5.5	50	85	A	2 607 010 522	P1k	4	1	446068	
6.0	60	100							
7.0	60	100							
8.0	80	120							



Set size D:
197.0 x 87.5 x 23 mm

7-piece Robust Line CYL-9 Multi Construction multi-purpose drill bit set								
4.0	40	75	D	2 607 010 543	P1k	7	1	446273
5.0	50	85						
6.0	60	100						
6.0	60	100						
8.0	80	120						
10.0	80	120						
12.0	90	150						
5.0	50	85	D	2 607 010 546	P1k	7	1	446303
5.5	50	85						
6.0	60	100						
6.0	60	150						
7.0	60	150						
8.0	80	150						
10.0	80	150						