

Datasheet

RS Red Hookup Wire, UL1007/UL1569, 300 V CSA cUL TR-64 90C 300V FT1, cUL1007 / cUL 1569, RoHS GuideLine 24 AWG

RS Stock number 811-7572



Product Code: UL 1007 / UL1569 24AWG PVC

Product Description

Application:

general application and according to customer


Multi-construction

Single

Construction

Single	Tinned copper
AWG	24
Construction	T0.20±0.008x7
Stranded Dia.(mm)	0.61
Jacket	PVC
Nom.Thickness	0.41
Jacket Dia.(mm)	1.42±0.08
Insulation Color	See Table Below


Marking(3times/Per meters)

Exxxxxx  AWM STYLES 1569 105C OR 1007 80C VW-1 300V 24 AWG

PACKAGING

100M/Cardboard Reel

Design

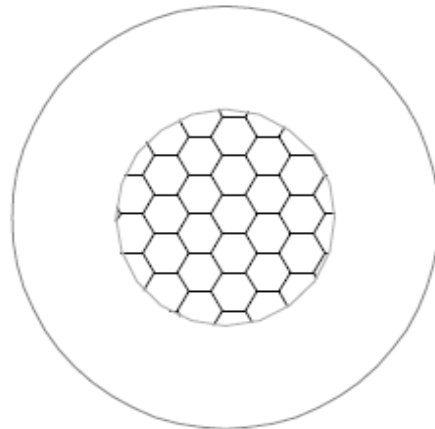

Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω /Km)		86
Rated Temperature(°C)	AWM/Style 1007	80
	AWM/Style 1569	105
	CSA TR-64	90
Rated Voltage(V)		300
20°C Insulation Resistance(M Ω .KM)		> 200