


## Features

- Material: UL approved Nylon 66, 94V-2.
- Color: Black
- Feature: Low Smoke and Halogen Free cable tie suitable for various industry, also household DIY and gardening.
- Application: One piece self-lock cable tie save the time and make effective for installation.
- UV resistant cable tie: for outdoor use with UV feature.
- Easy to thread.

## RS PRO Cable Ties

RS Stock No.: 8111482

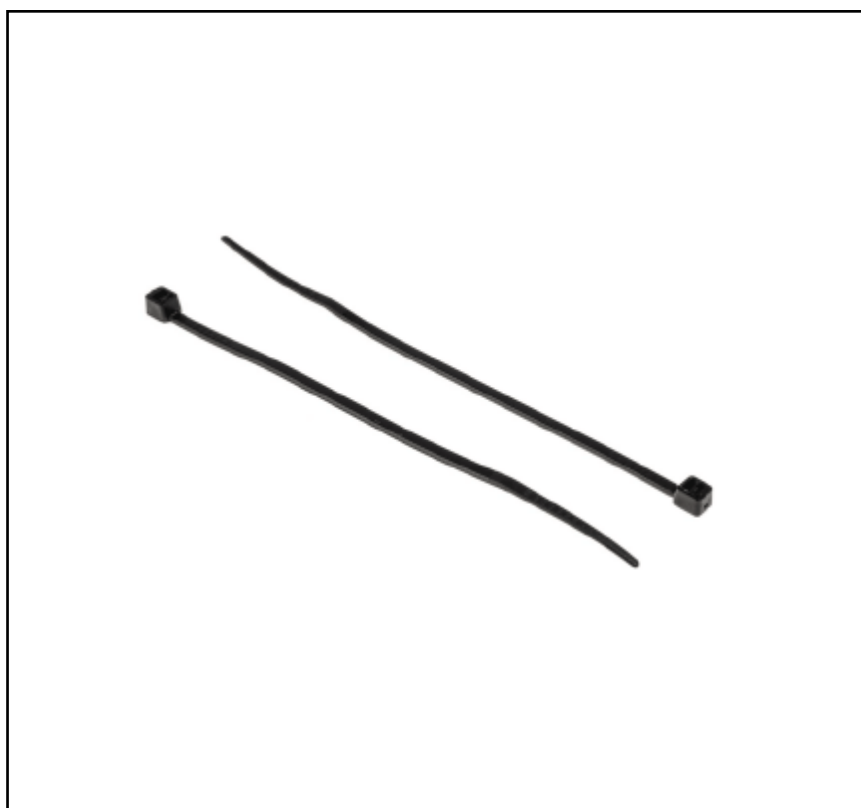

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

*These cable ties are made from Nylon 66(also known as nylon 6.6), The ties are suitable for binding components or cable and have a non-release ratchet lock action. Ideal for cable and wire management.*

## General Specifications

Type	Non-Releasable
Colour	Black
Material	Nylon 66
UV Resistant	No
Minimum Operating Temperature	-40°C
Maximum Operating Temperature	85°C
Fire Behaviour	Self-Extinguishing
Packing	250

## Mechanical Specifications

Length	100mm / 4"
Width	2.5mm / 0.1"
Min. Loop Tensile Strength(lbs/kgf/N)	18lbs / 8kgf / 80N
Maximum Bundle Dia.	22mm

## Approvals

Standards Met	UL, RoHS, SVHC, DNV.GL, Lloyd's, CE, VDE, ABS, HF
---------------	---

