


Category 6A 24 Port 1U STP Coupler Panel

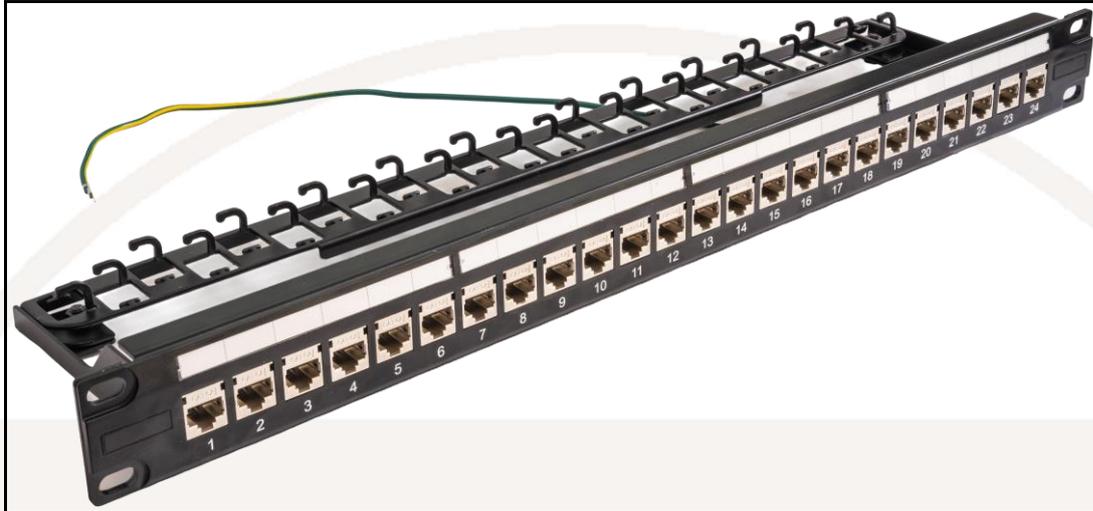

Category 6A 24 Port 1U STP Coupler Panel (SGFACK24)

TUK's horizontal Category 6A 1U STP coupler panel offers high performance in a compact package.

Features

- High performance, accommodates Category 6A at 10G
- Compliant with IEEE standard for PoE+ and 4PPoE IEEE 802.3
- Fully shielded die-cast coupler housings are robust as well as offering outstanding performance in eliminating alien cross-talk
- Clear numbering on the front provides a quick, easy way to identify cable run
- Slip-in label facility for port identification
- Supplied with a removeable rear cable management bar, 2 sets of M6 black cage nuts and 270mm long earth wire with fixing screws
- Thicker gold plating on contacts accommodates multiple re-patching.

Specifications

- Weight: 1386g approx.
- Dimensions: 520mm x 80mm x 65mm (W x D x H) approx. in primary packaging
- Colour:
 - front: black + silver
 - rear: black
- Materials:
 - Panel: cold-rolled steel with polycarbonate plastic facia
 - Rear of panel and cable management: cold-rolled steel with black coating

Contacts: 50µ"/1.27µm gold plating over nickel over phosphor bronze
Coupler housing: Zinc alloy

Packaging: Supplied assembled in an individual carton


EAN: 5055386512758

Commodity Code: 85177090

Country of Origin: China


For further information on components, please see links below:

SGACK2S <https://tuk.co.uk/product/category-6a-shielded-keystone-coupler/>
FFK24mtmc <https://tuk.co.uk/product/24-port-empty-keystone-panel>

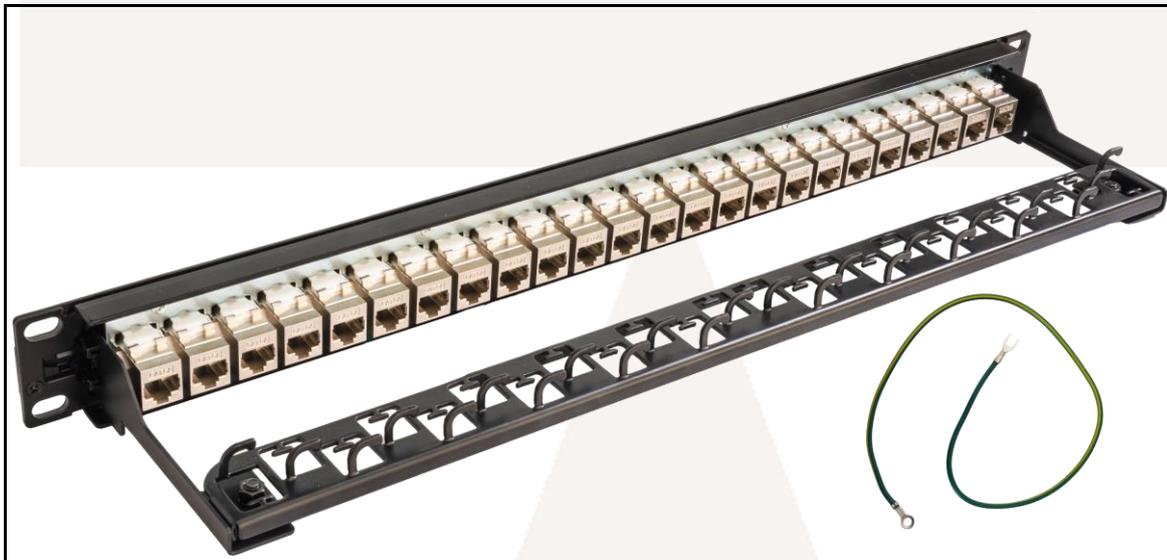

Earth lead supplied fitted to panel

ROHS Compliant

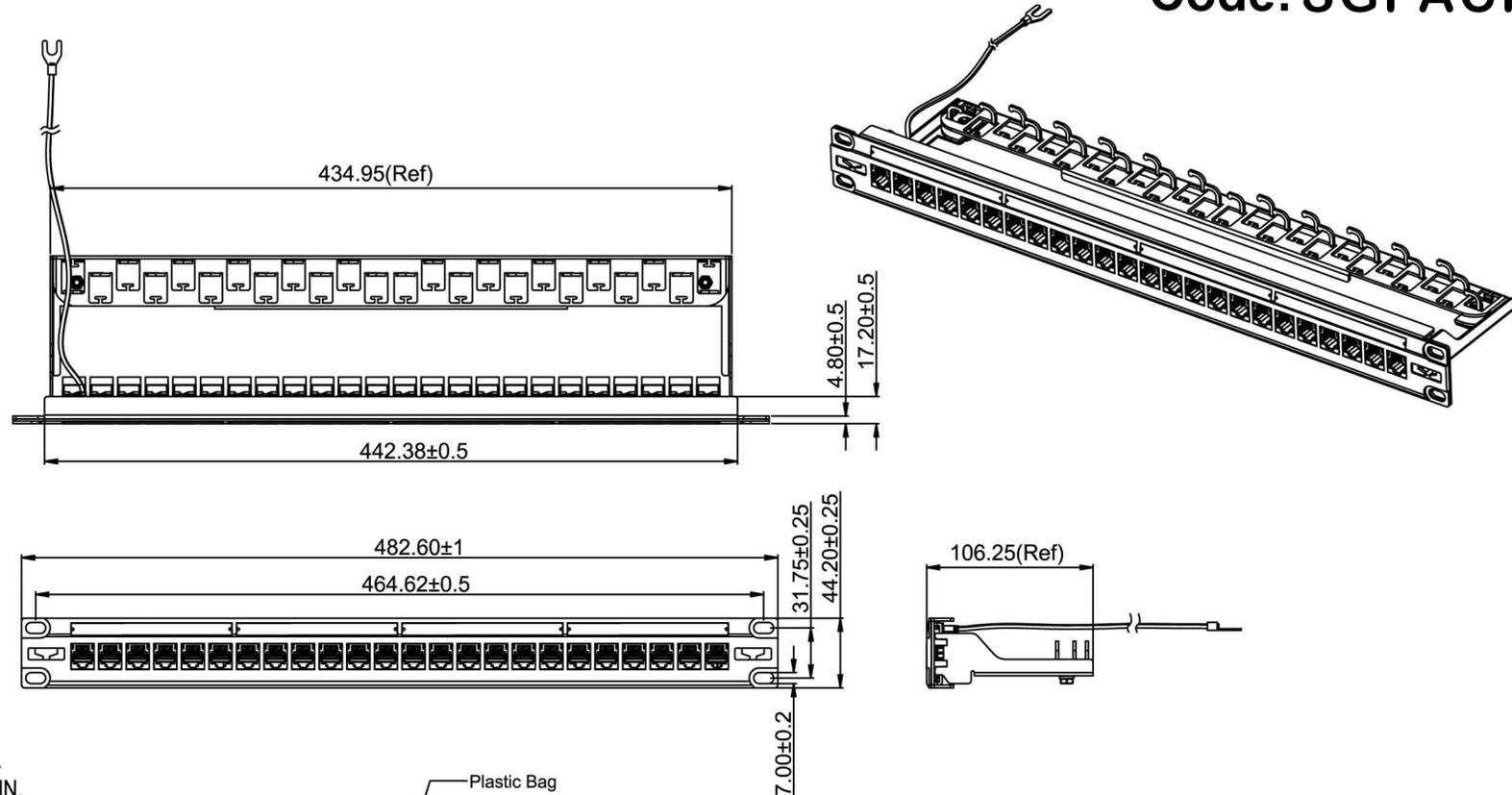

ELECTRICAL:

- Current Rating: 1.5A Max.
- Contact Resistance : 20m Ω MAX.
- Insulation Resistance : 500M Ω MIN.
- Dielectric Withstanding Voltage 1000V AC

MECHANICAL:

- Durability: 750 Mating Cycles
- Operating Temperature: -10°C to +60°C
- Storage Temperature: -40°C to +70°C

MATERIAL

- Metal Panel: Cold-rolled steel with black coating
- Plastic Front Panel: Polycarbonate
- Clear plastic Window: Acrylo-Styrene
- Cable Management left/right holder: Cold-rolled steel with black coating
- Coupler: Zinc Alloy

