

Product data sheet

179 N X-8/252

EAN-No. 4000896232413



252-pieces · 8 Drawers total



Application:

Efficient, mobile organisation of tools

- Tool trolley
- 7 flat and 1 high drawer
- Complete with 252-piece tool assortment in Safety-Insert-System soft foam insert

Work areas

- Much larger storage and work areas in plastic (179N) or stainless steel (179NX)
- Fully sealed work surface protects inside of trolley from leaking liquids
- Interfaces integrated in the work area for accessories such as laptop holders and top modules

Body / Pull-handle

- Extremely robust design thanks to dual-wall structure
- Complete welded construction of the entire body for tough daily workshop use
- Optimised, yielding edge protection on all four corners with real impact protection thanks to internal damping concept
- Ergonomically optimised pull handle for better manoeuvrability

Locking concept

- Ergonomically arranged side lock position for better operability protects keys and lock against damage
- Highly secure closing system with central locking technology for optimum protection of your property
- 2-stage locking
 - Central locking, lockable with cylinder lock and 2 folding keys
 - Mutual drawer locking for minimum tilting risk

Drawer concept

- Self-closing and reciprocal locking of the drawers prevents unwanted opening
- 100% sliding-out with ball-bearing telescopic slides
- Drawer design for optimum use of the interior
- Drawer fronts for optimised handling
- Dirt-resistant drawer coating for easy cleaning

High performance chassis

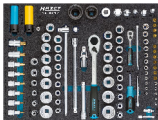
 
 
 
 
 
 
 
 
 
 
- Large wheels with high loading capacity, precision ball bearing and dual rounded rim in the pivot bearing, easy manoeuvrability, even with high dynamic load
- 2 swivel castors with dual brake:
 - Braked castors prevent rolling away
 - Braked swivel bearings prevent the swivel castors from turning, e.g. on inclined surfaces
- Protective ring prevents dirt and threads from getting in
- Elastic castors enable smooth movement

Assistant[®] **179N-6 – 9:**

- Solvent-resistant plastic work surface
- Metal handle, powder coated in black

Assistant® **179NX-6 – 8:**

- Stainless steel work surface
- Extra protection through high-quality plastic end caps
- Brushed stainless steel handle
- Total loading capacity (dynamic): 540 kg
- Loading capacity (static): 1000 kg
- Loading capacity of high drawer: 25 kg
- Colour: HAZET blue
- Tool trolley Made in Germany
- Dimensions: 785 mm x 518 mm x 1020 mm
- Net weight: 89 kg
- Drawers, flat: 7 × 81 x 522 x 398 mm
- Drawers, high: 1 × 166 x 522 x 398 mm
- (Drawer) size for plastic drawer insert: 3/3+
- Worktop: Stainless steel
- Number of fixed castors: 2 (Ø 125 mm)
- Number of swivel castors: 2 (Ø 125 mm)
- Number of tools: 252

Order Number		179NX-8/252	
 179NX-8	 163-369/104   163-221/10 • ○ •   990 • ○ •  M8 • M10 • M12 • M14 • M16 • M18	 850 •  •  4 • 5 • 5.5 • 6 • 7 • 8 • 9 • 10 • 11 • 12 • 13 • 14	 850E •  •  E4 • E5 • E6 • E7 • E8
 990LG • ○ •  M8 • M14	 990SLG • ○ •  M10 • M12	 8501 • ○ •  3 • 4 • 5 • 6	 8502 •  •  T10 • T15 • T20 • T25 • T27
		 8503 •  •  1 x 5.5	 8506 •  •  PH1 • PH2
		 858-1 •  •  • 	 863HP •  • 
		 811-UK •  • 	 867-2 •  • 
		 867-4 •  • 	 868 •  • 
		 869 •  • 	 8858-1 •  •  8858-2 •  • 
			 900 •  •  10 • 11 • 12 • 13 • 14 • 15 • 16 • 17 • 18 • 19 • 20 • 21 • 22 • 24 • 27 • 30 • 32
			 900E •  •  E10 • E12 • E14 • E16 • E18 • E20
			 900SZ •  •  32 • 36
			 900Z •  •  8 • 9 • 10 • 12 • 13 • 14 • 15 • 16 • 17 • 18 • 19 • 21 • 22 • 24 • 27 • 30 • 32

Product data sheet

179 N X-8/252

EAN-No. 4000896232413



903SLG • • 1/2
17 • 19



915 • 1/2



916HP • 1/2

919 • 1/2 • 1/2

919-1 • 919-5 • 919-10



920 • 1/2 • 1/2

958-1 • 3/4 • 1/2

958-2 • 3/8 • 1/2

992 • • 1/2

T25 • T27 • T30 • T40 •

T45 • T50 • T55 • T60

1058-2 • 1/2 • 3/4

2223N • • 1/4

T6 • T7 • T8 • T9

2250-1 • 1/4 • 1/4



163-372/25 •

612N •

10 x 11



666-5

730

730-3 • 730-6

746-1

748B

748B-3 • 748B-4 • 748B-5 •

748B-6 • 748B-8

824 •

0.5 x 23



1952-40



1976-2

2140-40

2147MS



2152N/3



2154N-5



2157-1



4968-2



163-374/27



600N •

6 • 7 • 8 • 9 • 10 • 11 • 12 •
13 • 14 • 15 • 16 • 17 • 18 •
19 • 21 • 22 • 24

630 •

6 x 7 • 8 x 9 • 10 x 11 •
12 x 13 • 14 x 15 • 16 x 17 •
18 x 19 • 21 x 22 • 24 x 27 •
30 x 32



163-511/4



760-2

1802M-22



1841MB-33

1850M-22



163-515/16 •

606 •

8 • 9 • 10 • 11 • 12 • 13 •
14 • 15 • 16 • 17 • 18 • 19



606/4SPC



163-526/41N



811 •

0.4 x 2.5 • 0.5 x 3 • 0.8 x 4 •
1 x 5.5 • 1.2 x 6.5



811PH •

PH0 • PH1 • PH2



811T •

T10 • T15 • T20 • T25 •
T27 • T30



811K •

0.6 x 3.5 • 1 x 5.5



811KPH •

PH1 • PH2



811S •

0.8 x 4.5 • 1 x 5.5 • 1.2 x 7



811SPH •

PH1 • PH2 • PH3



2105LG/9H •



2116LG/8H •



163-172X50



2128N-1