



ENGLISH

Datasheet

RS Pro Straining Screw, Hook to Eye, M6

RS Stock No: **674-005**



Product Details


RS Pro rigging screw is suitable for use with or tensioning wires or for securing loads or plant. This steel screw with electro galvanised finishing features hook to eye end fittings. The screw with M6 thread size, has a working load limit of 2t.

Features and Benefits

- A range of 4 sizes of hook and eye galvanised malleable straining screws
- Hook to eye end fittings
- M6 metric threading

Specifications:

Closed Length	172 mm
End A Fitting	Hook
End B Fitting	Eye
End Fittings	Hook to Eye
Eye Diameter	9 mm
Finish	Electro Galvanised
Material	Mild Steel
Open Length	258 mm
Thread Size	M6
Weight	0.11 kg
Working Load Limit	2 t

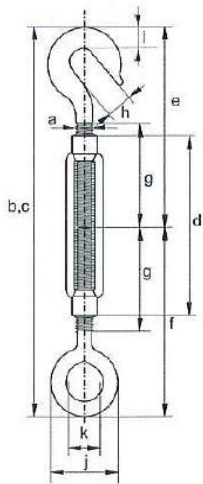

diameter thread	length closed position	length open position	length body	length endfitting	length endfitting	length thread	opening hook	thickness hook	diameter eye outside	diameter eye inside	weight each
a	b	c	d	e	f	g	h	i	j	k	kg
mm	mm	mm	mm	mm	mm	mm	mm	mm	mm	mm	
6	172	258	110	77	80	55	8	15	20	9	0.11
8	184	264	110	85	84	57	10.5	15	22	10	0.20
10	222	311	125	106	105	68	13	11	31	14	0.28
12	241	324	125	117	111	70	16	13	35	16	0.43
14	261	351	140	124	122	75	18	15	40	18	0.61
16	311	427	170	144	150	88	20	17	47	22	1.00
20	358	490	200	170	167	105	21	21	52	24	1.60
22	414	559	220	200	186	118	24	28	60	27	2.20
24	453	630	255	215	205	135	26	33	65	27	2.80
30	495	660	255	240	220	135	34	35	71	31	4.10
33	545	744	295	260	245	148	38	40	88	36	6.00
36	597	782	295	275	277	158	46	45	94	38	8.40