




Navigation LED P28s 100V-240V AC 8W (72W) 1000lm 865 IP20

Article number: 143287

BAI Navigation LED P28s 8W 6500K IP20 1000lm (72W) 120V-130V 230V-240V 50/60Hz 33x106mm Marine / Ship lamp

Navigation LED lamp with P28s prefocus base for ship position lights. Due to its retrofit size and high lumen output these lamps are ideal replacements for conventional navigation lamps. Wide voltage range (AC) to suit multiple applications, frequency of 50/60Hz, all-around illumination and long life. Ambient temperature range: -20°C tot +40°C.

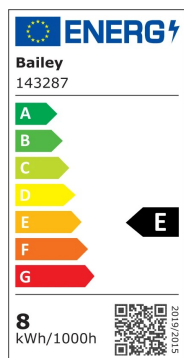

General ETIM properties

ETIM group	Lamps
ETIM class	Vehicle lamp
Name	Navigation LED P28s 100V-240V AC 8W (72W) 1000lm 865 IP20
Brand	Bailey
Productseries	Marine LED
Producttype	NAV P28S 865

ETIM specifications

Socket	P28s
Lamp voltage [V]	100 - 240
Lamp power filament 1 [W]	8
Diameter [mm]	33
Total length [mm]	106
Colour	White
Technology	LED
Luminous flux [lm]	1000
Amperage [A]	0.62
Lamp efficacy [lm/W]	125
Suitable for head light passenger car	No
Suitable for head light truck	No
Suitable for other lighting passenger car	No
Suitable for other lighting truck	No
Suitable for vessel	Yes
Suitable for bicycle	No
Suitable for moped	No
Suitable for motorbike	No
Suitable for rail traffic	No
Suitable for planes	No
Suitable for forklifts	No
Standard indication (ECE)	Other

Alternative articles



70500036501

Navigation LED P28s 100V-240V
AC 5W (48W) 600lm 860 IP20