


**90311-014LF - Minitek™ : Crimp-to-Wire
Housing, Double Row, Pol. w/Latch, 14
Position**

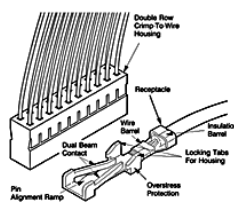

www.fci.com

Specifications

Approvals / Certifications

UL File Number	E66906
CSA File Number	LR46923
Approvals / Certifications	UL and CSA Approved

Mechanical

Durability (Mating cycles)	100
----------------------------	-----

Electrical

Withstanding Voltage	650V rms
Current rating	2 amp Continuous
Resistance (Insulation)	1000 M ohms min

General

Number of contacts (Total)	14
Number of rows	2
Product Type	Crimp-to-Wire Housing
Mating half	Mates with 0.5 (0.02 in.) Square Pin. Mating Pin Length of 3.63 to 4 mm (0.143 to 0.157 in.)

Other Features

Packaging (Type)	Bag
Center Key Slot	Yes

Physical

Color (Housing)	Black
Material (Housing)	Thermoplastic
Temperature (Operating - range)	-40°C to +105°C