


Fully Preinsulated Female Disconnects



General features

- ✓ Tin-plated brass double crimp “S” version.
- ✓ Copper sleeve for crimping insulation giving better resistance to vibration.
- ✓ Polycarbonate insulation sleeve.
- ✓ Max. operating temperature: +125°C.
- ✓ Flammability rating: UL94V0.

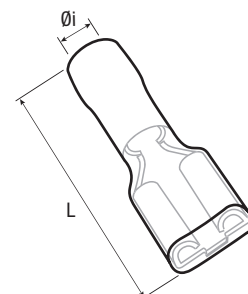

mm ²	Bulk packing		x100 /Box		Ø mm	Male disconnect		Ø i	L	
	Item code	Part No.	Item code	Part No.		Width	Thickness			
0.34 - 1.5	7252010	SQAP2,8-5	7252012	B100SQAP2,8-5	3.2	2.8	0.5	1.7	19.5	●
	7252013	SQAP4,8-5	7252014	B100SQAP4,8-5	3.6	4.8	0.5	1.7	20	●
	7252001	SQAP4,8-8	7252002	B100SQAP4,8-8	3.6	4.8	0.8	1.7	20	●
	7252021	SQAP6,35	7252023	B100SQAP6,35	2.9	6.3	0.8	1.7	23.5	●
1 - 2.5	7252047	SQBP4,8-5	7252055	B100SQBP4,8-5	4.3	4.8	0.5	2.4	20	●
	7252060	SQBP4,8-8	7252062	B100SQBP4,8-8	3.4	4.8	0.8	2.4	20	●
	7252063	SQBP6,35TH2	7252064	B100SQBP6,35TH2	3.4	6.3	0.8	2.4	23.5	●
2.6 - 6	7252041	SQCP6,35	7252058	B100SQCP6,35	5.5	6.3	0.8	3.6	26	●



Conductor size (mm²)



Packing



Cable insulation max Ø

Unless otherwise stated, all dimensions are in millimeters.