


Datasheet

PUR 10m Long transparent Flexible Ducting Reinforced, 150mm Bend Radius , Applications Various

RS Stock number 362-2158

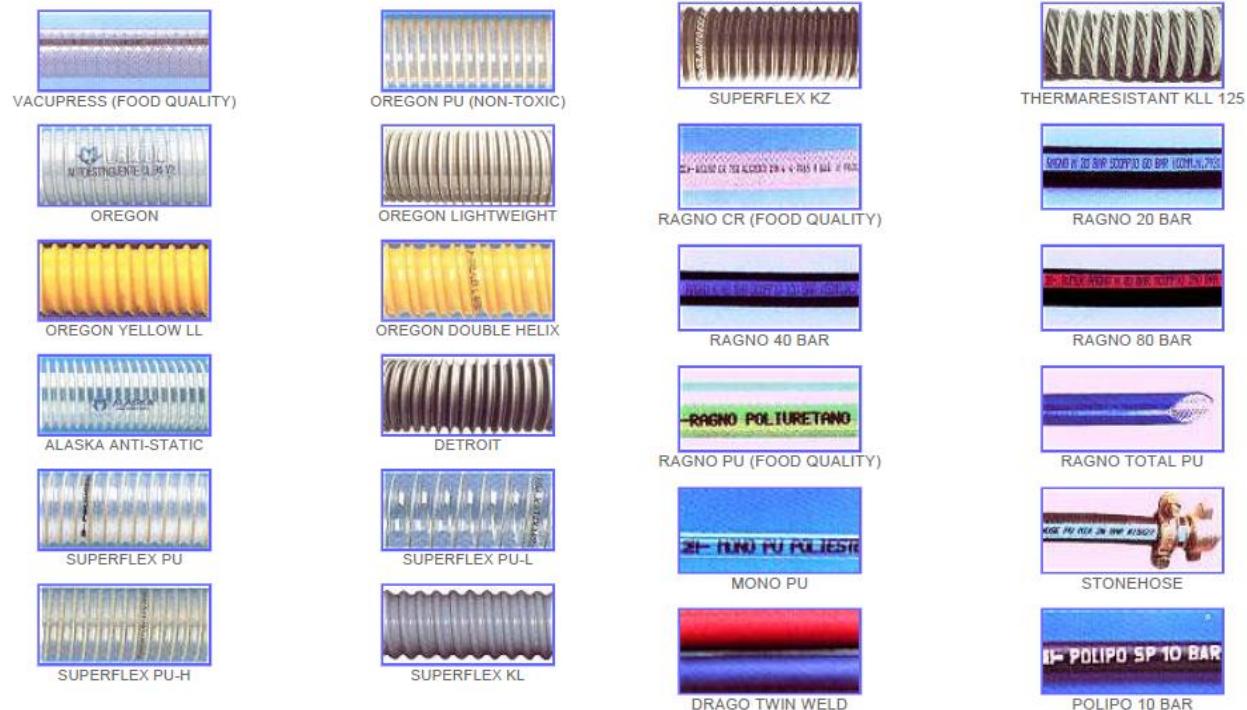

**ENGLISH****SUPERFLEX PU-L**

Code 410

I.D. mm.	Weight gr./mtr.	Bending Radius mm.	Vacuum m.H ₂ O	Working Pressure bar
30	130	7	0.30	0.60
35	140	8	0.28	0.55
40	150	10	0.25	0.50
50	185	13	0.20	0.45
60	220	15	0.16	0.40
63	230	16	0.15	0.38
70	330	18	0.14	0.35
76	350	19	0.10	0.30
80	370	20	0.10	0.27
90	420	22	0.10	0.23
100	480	20	0.09	0.20
110	520	22	0.09	0.20
120	550	24	0.09	0.19
125	590	25	0.08	0.19
130	610	26	0.08	0.18
140	660	28	0.08	0.15
150	700	30	0.06	0.11
160	750	32	0.06	0.10
170	780	34	0.06	0.09
180	830	36	0.06	0.09
200	920	40	0.05	0.08
220	1070	45	0.05	0.07
250	1250	50	0.04	0.05
300	1500	60	0.03	0.03
350	1750	70	0.03	0.02
400	2000	80	0.02	0.02
450	2300	90	0.01	0.01
500	2500	100	0.01	0.01
600	3000	120	0.01	0.01

Note: Coil length details on request.

All data refers to performance at 18°C. Any increase of temperature, above or below, will affect the performance data.
We reserve the right to change all technical data without prior notice.