

Wall Mount Distribution Box for 4FO cables



TECHNICAL SPECIFICATION



GENERAL

The wall mount distribution box can hold up to 4 FO and is suitable for indoor and outdoor applications.



It has one entry hole for a multifibre cable with a maximum diameter of 10 mm and four exit holes for simplex patchcords with a maximum diameter of 3 mm.

PRODUCT DESCRIPTION

The plastic box has a lock with a universal key and is made up of two separate sections:

One for the incoming cables and the output patchcords,
the other for the splicing area.

- The cable entry gland can hold one cable with a maximum diameter of 10 mm.
The cable can be held in place with a strap and the strength member with a screw clamp.
- The splicing area can manage up to 4 protection sleeves.
- The termination area has plastic frames to hold 4 SC sx adapters, 2 LC dx adapters or any other adapter with a rectangular flange.
- Each of the four patchcord outputs has a rubber seal with one hole.
The max diameter of the output patchcords is 3 mm.
- The box is supplied with a fiber winding kit and wall fixing accessories.

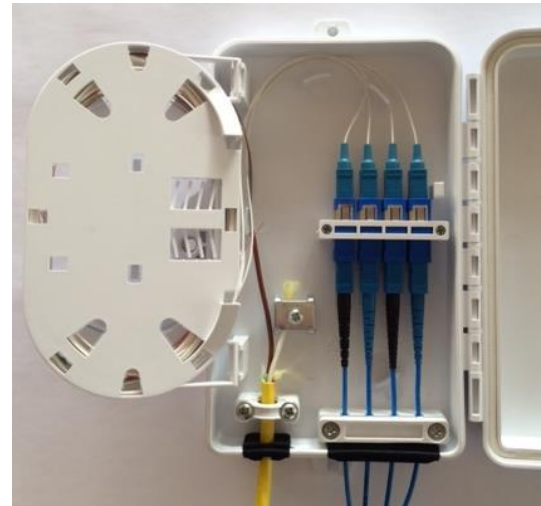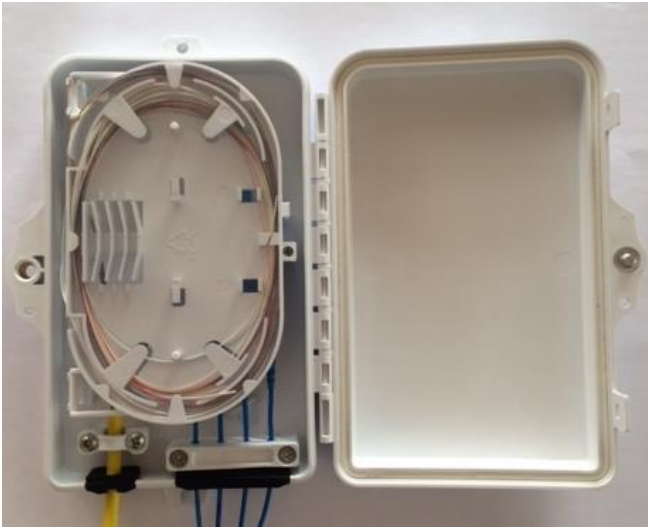

C H A R A C T E R I S T I C S

- Size 207x 135 x 45 mm
- Colour White
- RoHS and REACH Compliant
- Protection grade IP65
- Operating temperature -40 / +70 °C
- Mounting Wall mounting kit included
Accessory kit for pole mounting not included
- Material PC + ABS

E N D O F S P E C I F I C A T I O N