


**DIN 3118**

- Bocche aperte per la manovra di raccordi di impianti idraulici, oleodinamici ed aria compressa.

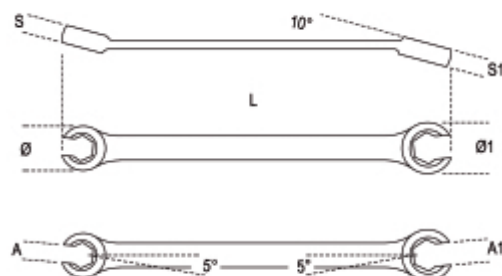

|   |  | art.     |  mm | L mm | Ø mm | Ø1 mm | A mm | A1 mm | S mm | S1 mm | g   |
|---|-----------------------------------------------------------------------------------|----------|--------------------------------------------------------------------------------------|------|------|-------|------|-------|------|-------|-----|
| ○ | 000940008                                                                         | 94 8X10  | 8x10                                                                                 | 140  | 17,8 | 19,3  | 6,0  | 7,0   | 6,5  | 7,5   | 40  |
| ○ | 000940009                                                                         | 94 9X11  | 9x11                                                                                 | 153  | 19,4 | 21,4  | 7,0  | 9,0   | 8,0  | 8,5   | 49  |
| ○ | 000940010                                                                         | 94 10X11 | 10x11                                                                                | 153  | 19,4 | 21,4  | 7,0  | 9,0   | 8,0  | 8,5   | 70  |
| ○ | 000940011                                                                         | 94 11X13 | 11x13                                                                                | 175  | 21,4 | 23,5  | 9,0  | 8,5   | 8,5  | 10,5  | 80  |
| ○ | 000940012                                                                         | 94 12X14 | 12x14                                                                                | 175  | 22,8 | 25,3  | 9,0  | 11,0  | 8,5  | 10,5  | 78  |
| ○ | 000940013                                                                         | 94 13X15 | 13x15                                                                                | 175  | 25,7 | 27,7  | 10,5 | 12,1  | 11,0 | 11,4  | 102 |
|   | 000940014                                                                         | 94 14X15 | 14x15                                                                                | 175  | 25,5 | 27,3  | 11,0 | 12,0  | 10,5 | 11,0  | 130 |
|   | 000940015                                                                         | 94 14X17 | 14x17                                                                                | 195  | 27,4 | 31,4  | 11,0 | 14,0  | 11,0 | 12,5  | 140 |
|   | 000940017                                                                         | 94 17X19 | 17x19                                                                                | 212  | 31,2 | 33,3  | 14,0 | 15,0  | 12,0 | 13,0  | 174 |
|   | 000940019                                                                         | 94 19X22 | 19x22                                                                                | 228  | 33,5 | 38,5  | 15,0 | 17,0  | 13,0 | 14,0  | 220 |
|   | 000940022                                                                         | 94 22X24 | 22x24                                                                                | 242  | 38,5 | 42,0  | 17,0 | 18,0  | 15,0 | 16,0  | 314 |
|   | 000940024                                                                         | 94 24X27 | 24x27                                                                                | 260  | 46,6 | 46,6  | 18,0 | 20,0  | 16,0 | 17,0  | 411 |
|   | 000940030                                                                         | 94 30X32 | 30x32                                                                                | 300  | 50,6 | 52,6  | 22,0 | 24,0  | 19,0 | 20,5  | 672 |
|   | 000940036                                                                         | 94 36X41 | 36x41                                                                                | 320  | 61,0 | 67,5  | 25,5 | 32,5  | 24,5 | 25,4  | 772 |