


Data Specification Sheet

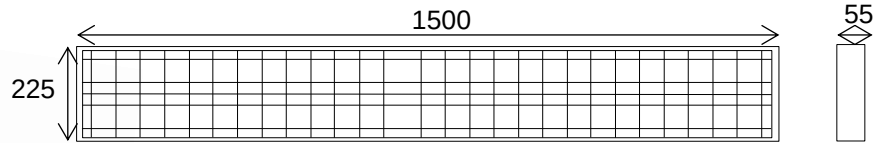

SURF235HF Surface T5 2x35W Fluorescent Luminaire

ML Accessories Code	SURF235HF. SURF235EMHF
Wattage	2x35W
Description	High Frequency T5 35W Fluorescent Prismatic
Finishes available	White
Overall dimensions	See above diagram
Fixing Centres	4 x Fixings 1035 x 170
Weight	5kg (4kg EM Version)
Typical location	Indoor or Outdoor
Lamp Supplied	No
Voltage (V)	220-230V 50Hz
Class	Class I. Must be Earthed
IP	IP20
Photometric Testing	Yes
Instruction sheet	Yes
Origin of manufacture	China
Main materials:	
Body	Powder Coated Mild Steel
Louvre	Aluminium
Method of fix	Direct to ceiling
Lamp holder cap	G5
Lamp type	T5 35W
Electrical Connections	L.E.N. Nylon Connector, Screw Terminals
Running Gear / Make /Operating Temperature	Knightsbridge H.F. Electronic ballast - 20°C to +30°C Knightsbridge H.F. Emergency 3 hour inverter (integral)
Dimmable	No
Cold Store Version -20°C	No
F mark	Yes
CE mark	Yes
Quality Assurance System	Yes ISO 9001 QMS
Batch coding details	Yes
Certificate of Conformity	Yes
Manufactured in accordance	EN60598
Guarantee Period	1 Year