
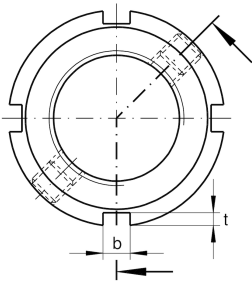


ZMA20/52

Precision locknut

Precision locknuts ZMA, locking pegs, radially arranged, heavy series

Technical information

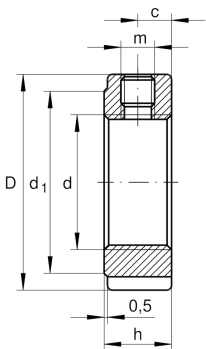

Main Dimensions & Performance Data

d	M20X1	Thread
D	52 mm	Outside diameter
h	25 mm	Height
M _A	3 Nm	Mounting torque set screw
F _{aB}	218,000 N	Breaking load, axial
M _L	40 Nm	Breakawag
M _{AL}	18 Nm	Mounting torque reference
M _M	1.38 kg*cm ²	Mass moment of inertia

≈m 320 g Weight

Dimensions

d ₁	47 mm	Plant diameter outside
t	2 mm	Hight retaining slot
b	5 mm	Width retaining slot
c	12.5 mm	Distance bore
m	M5	Threaded - threaded pin