


Datasheet

RS PRO Female SMA to Female UFL, 200mm Coaxial Cable Assembly

RS Stock number [794-2838](#)

Dimensions: (mm)

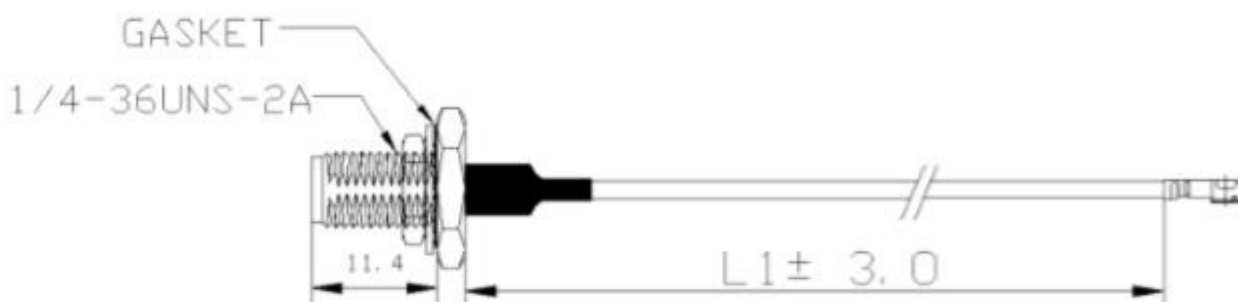

Specifications

PRODUCT MATERIAL

- 1. SMA B/H JACK CRIMP TYPE FOR $\varnothing 1.37\text{mm}$ CABLE NUT x WASHER x 1
- U.FL-LP-088 Halogen Free For $\varnothing 1.37\text{mm}$ Cable
- U.FL-088 CONTACT For $\varnothing 1.37\text{mm}$ Cable
- 1.37mm CABLE TIN PLATED COLOR:BLACK
- HEAT SHRINK TUBE F32 $\varnothing 2.5\text{mm}$ L=15.0mm COLOR:BLACK

ELECTRICAL PERFORMANCE

- IMPEDANCE:50 OHMS
- FREQUENCY RANGE:DC~3GHz
- WORKING VOLTAGE:250Vrms MAXIMUM 4.DIELECTRIC WITHSTANDING VOLTAGE:750Vrms min