


Cooker Control Units

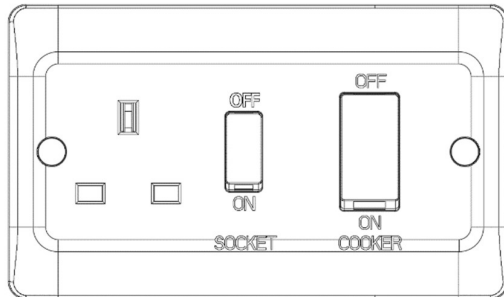

Description

This uniquely shaped range, in the Vimark Pro style, is easy to install with bold terminal markings and is supplied in individual protective polybags suitable for display.

This wide range includes neon versions, and an option of red or white switches.

Features

- Contemporary designed profile
- Concave rockers
- Switches rated at 45A
- Only one size 4mm screwdriver needed
- Terminals have clear bold markings
- Neon versions available
- 2 earth terminals
- Terminals have large lead-ins
- 25-year guarantee

Technical Specification

Voltage rating	250Vac
Current Rating	45A
Contact gap	3mm
Front plate material	Urea formaldehyde

Urea flammability classification UL94 grade V-C

No user serviceable parts

Standards

- BS 4177-4

Range

Cooker control unit – red switch	VP1302
Cooker control unit, neon – red switch	VP1302N
45A cooker cable outlet	VP1217

Back Boxes

Minimum recommended depth

	Flush 25mm	Dry lining 35mm	Surface 25mm
2g	DB168	DB2543	VP1229

Terminal Capacity

	6mm ²	10mm ²
L & N	2	1